

FL2-R270024A0-0D00



FL2000 Fiber Termination Panel, 24 SC/UPC, singlemode, 2RU, 19 in, putty white

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch panel
Product Series	FL2000

General Specifications


Functionality	Patching
Adapter Packs Included, quantity	4
Color	Putty white
Growth Configuration	Fully loaded
Interface, front	SC/UPC
Rack Type	EIA 23 in
Rack Units	2
Shelf Movement	Hinged
Splicing Capacity, maximum	0
Total Ports, quantity	24

Dimensions

Height	88.9 mm 3.5 in
Width	482.6 mm 19 in
Depth	256.54 mm 10.1 in

Ordering Tree

FL2-R270024A0-0D00

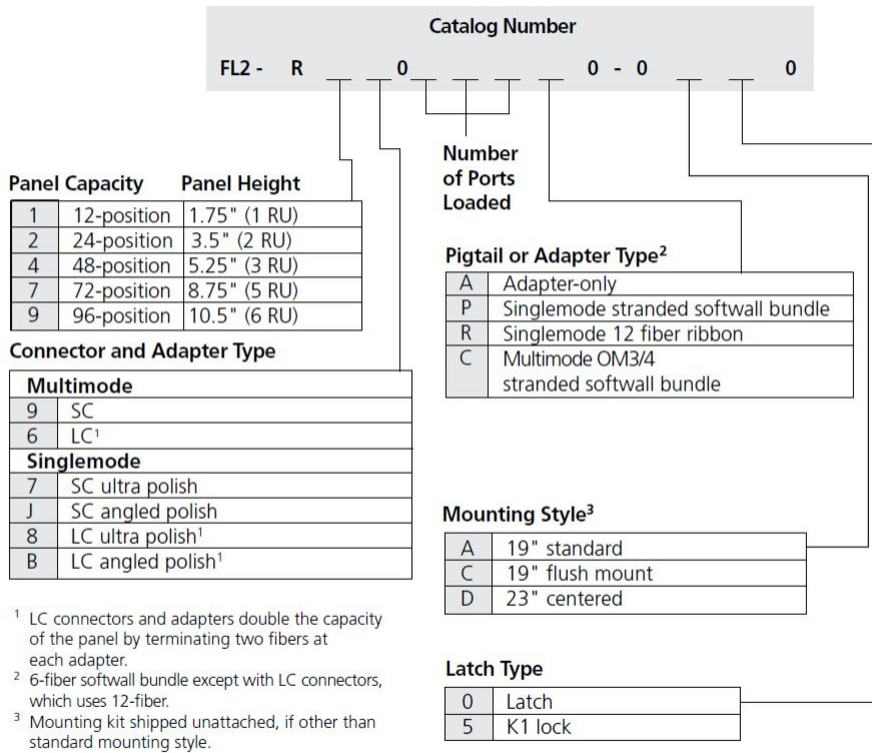

Material Specifications

Finish Powder coated

Material Type Steel

Optical Specifications

Fiber Mode Singlemode

Environmental Specifications

Operating Temperature -40 °C to +70 °C (-40 °F to +158 °F)

Storage Temperature -40 °C to +85 °C (-40 °F to +185 °F)

Packaging and Weights

Included Mounting hardware

Packaging quantity 1

Regulatory Compliance/Certifications

FL2-R270024A0-0D00

Agency**Classification**

CHINA-ROHS

Above maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant/Exempted

UK-ROHS

Compliant/Exempted

