

FL2-SD40YA010-CU00

FL2000 Fiber Termination Panel, 48 ST/UPC, singlemode, 3RU, 19 in, putty white, pre-terminated with IFC cable, 10 meters, Stub tail at far end

OBSOLETE

This product was discontinued on: March 1, 2018

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch panel, with IFC cable
Product Series	FL2000

General Specifications

Functionality	Patching
Adapter Packs Included, quantity	8
Cable Exit Location	Upward
Cable Stub Type	IFC
Color	Putty white
Color, front	Putty white
Growth Configuration	Fully loaded
Interface, front	ST
Interface Feature, front	Standard
Interface, rear	Stub tail
Patching Capacity, maximum	48
Rack Type	EIA 19 in
Rack Units	3
Shelf Movement	Hinged
Splicing Capacity, maximum	0
Total Ports, quantity	48


Dimensions

Height	133.35 mm 5.25 in
---------------	---------------------

FL2-SD40YA010-CU00

Width	482.6 mm 19 in
Depth	256.54 mm 10.1 in
Cable Stub Length	10 m 32.808 ft

Ordering Tree

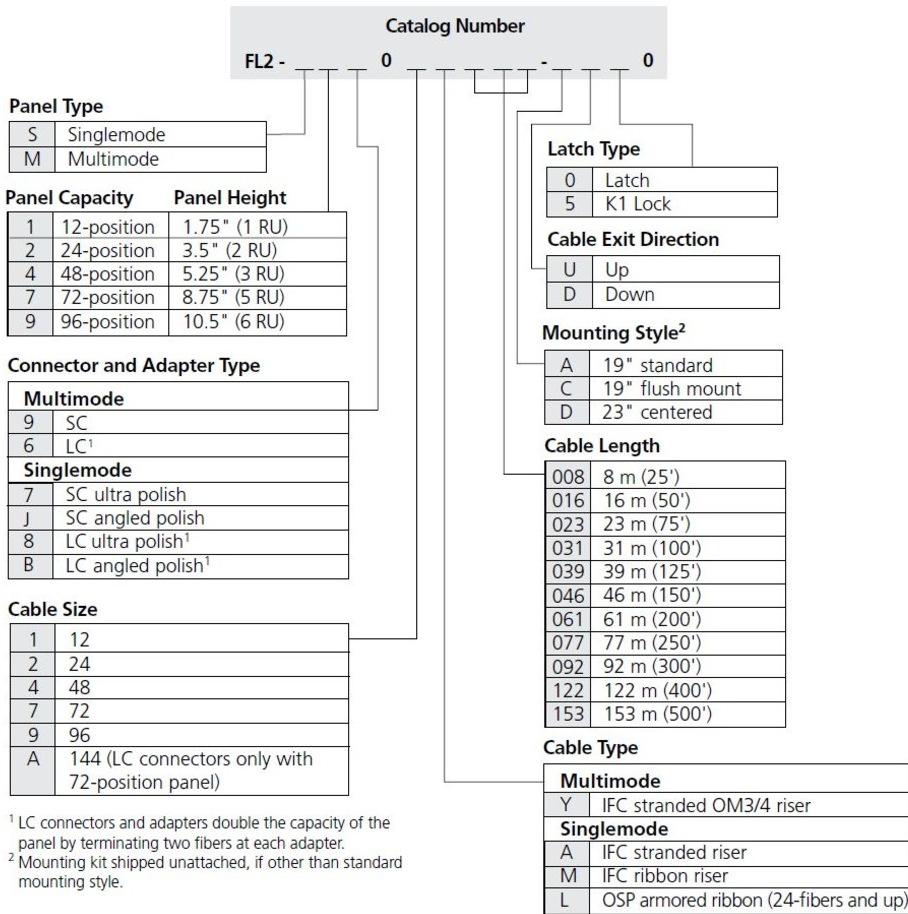

Material Specifications

Finish	Powder coated
Material Type	Steel

Optical Specifications

Fiber Mode	Singlemode
-------------------	------------

Environmental Specifications

FL2-SD40YA010-CU00

Operating Temperature -40 °C to +70 °C (-40 °F to +158 °F)

Storage Temperature -40 °C to +85 °C (-40 °F to +185 °F)

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Above maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant/Exempted

