

TFP-24APRQ5SR3

TFP Fiber Optic Adapter Pack, 24-fiber, Singlemode, LC, quad, right, blue, with pigtails, 3 meters

Product Classification

Regional Availability	Asia Latin America North America
Portfolio	NETCONNECT®
Product Type	Fiber adapter pack with pigtails
Product Series	TFP

General Specifications


Application	For use with TFP panels
Adapter Color	Blue
Adapters, quantity, front	6
Body Style	Quad Right orientation
Color, front	Black
Interface	LC/UPC
Pigtail Assembly Type	Color-coded, 900 µm Pigtail bundle
Pigtails Included, quantity	24
Total Fibers, quantity	24
Total Ports, quantity, front	24

Dimensions

Height	33.53 mm 1.32 in
Width	176.02 mm 6.93 in
Pigtail Length	3 m 9.843 ft

Ordering Tree

TFP-24APRQ5SR3

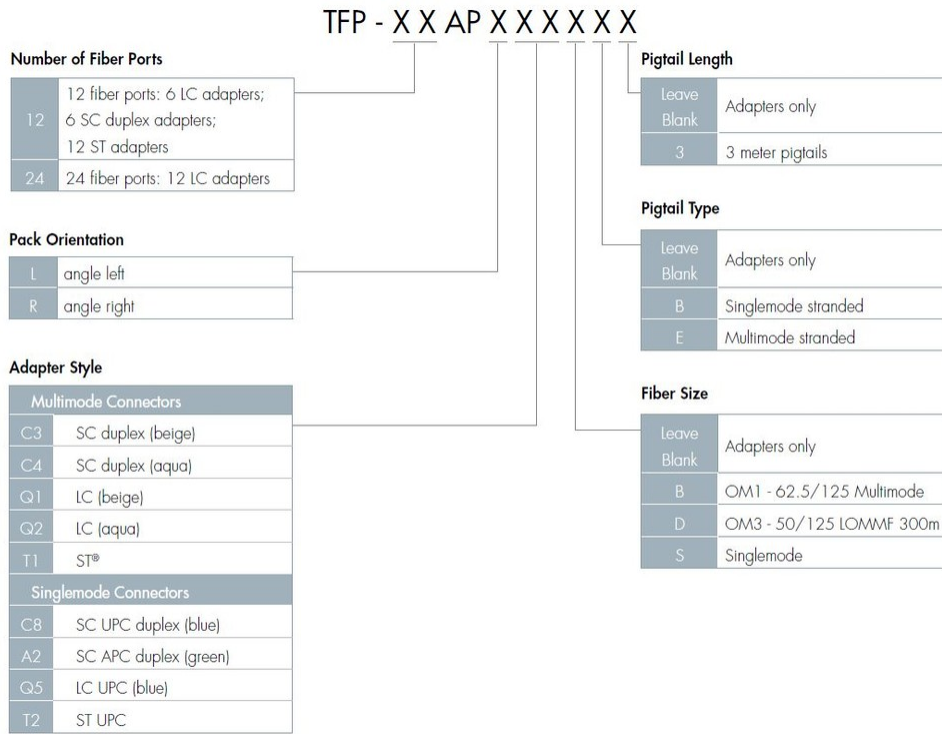

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	OS2
Insertion Loss, maximum	0.3 dB
Return Loss, minimum	55 dB

Environmental Specifications

Operating Temperature	0 °C to +70 °C (+32 °F to +158 °F)
Storage Temperature	-40 °C to +70 °C (-40 °F to +158 °F)

Packaging and Weights

Packaging quantity	1
Packaging Type	Bag Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value

TFP-24APRQ5SR3

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant/Exempted

UK-ROHS

Compliant/Exempted

