

# TFP-72APOMP

---



TFP Fiber Optic Adapter Pack, 72F, MPO

## Product Classification


<b>Regional Availability</b>	Asia   Latin America   North America
<b>Portfolio</b>	NETCONNECT®
<b>Product Type</b>	Fiber adapter pack
<b>Product Series</b>	TFP

## General Specifications

<b>Adapter Color</b>	Black
<b>Adapters, quantity, front</b>	6
<b>Body Style</b>	Simplex   Straight orientation
<b>Color, front</b>	Black
<b>Interface</b>	MPO
<b>Total Ports, quantity, front</b>	72

## Ordering Tree

# TFP-72APOMP

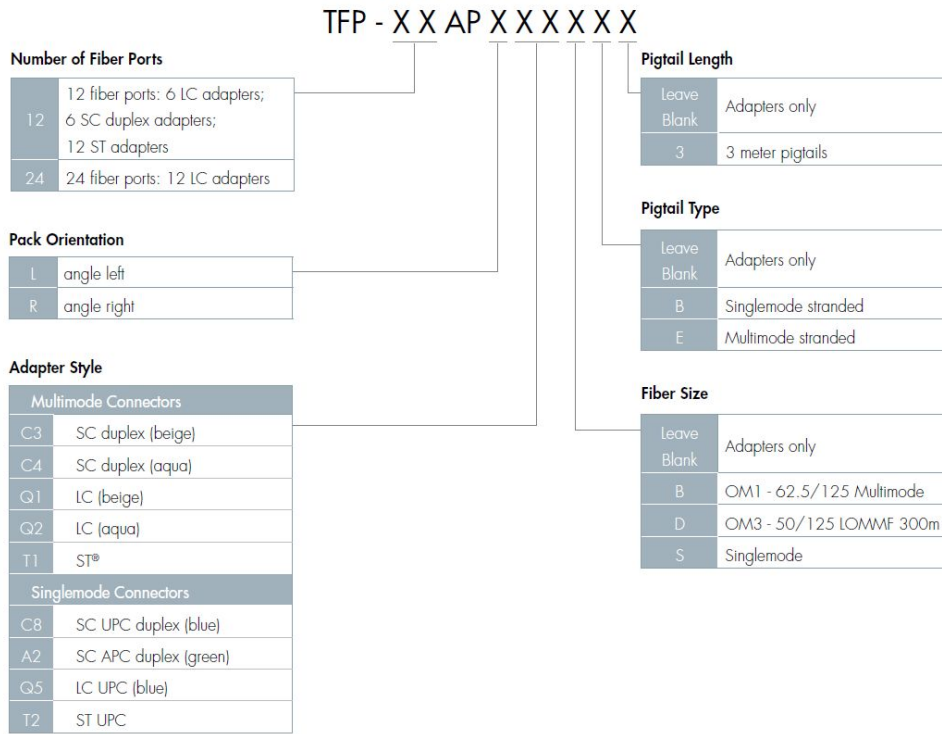

## Optical Specifications

**Fiber Mode** Multimode | Singlemode

## Environmental Specifications

**Operating Temperature** 0 °C to +70 °C (+32 °F to +158 °F)

**Storage Temperature** -40 °C to +70 °C (-40 °F to +158 °F)

## Packaging and Weights

**Packaging quantity** 1

**Packaging Type** Bag | Carton

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

# TFP-72APOMP

---

