


FJVMMPAH

Base Product

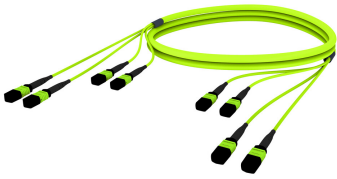

OM5 MPO (Unpinned) to MPO (Unpinned), InstaPATCH® 360 Pre-terminated Trunk Cable, 48-Fiber, Low Smoke Zero Halogen

- LazrSPEED® WideBand extends the capability of OM4 across enough spectrum to support at least four low-cost wavelengths

Product Classification

Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Fiber trunk cable assembly

Product Brand

SYSTIMAX InstaPATCH® 360

Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications

Color, boot A

Black

Color, connector A

Lime green

Color, boot B

Black

Color, connector B

Lime green

Construction Type

Stranded

Furcation Color

Lime green

Interface, Connector A

MPO-12/UPC Female

Interface, Connector B

MPO-12/UPC Female

Jacket Color

Lime green

Polarity

Method B (LL)

Fibers per Subunit, quantity

12

Total Fibers, quantity

48

Dimensions

Breakout Length

33 in

Cable Assembly Length Range (m)


3 – 999

FJVMMPAH

Cable Assembly Length Range (ft)

10 – 999

Ordering Tree

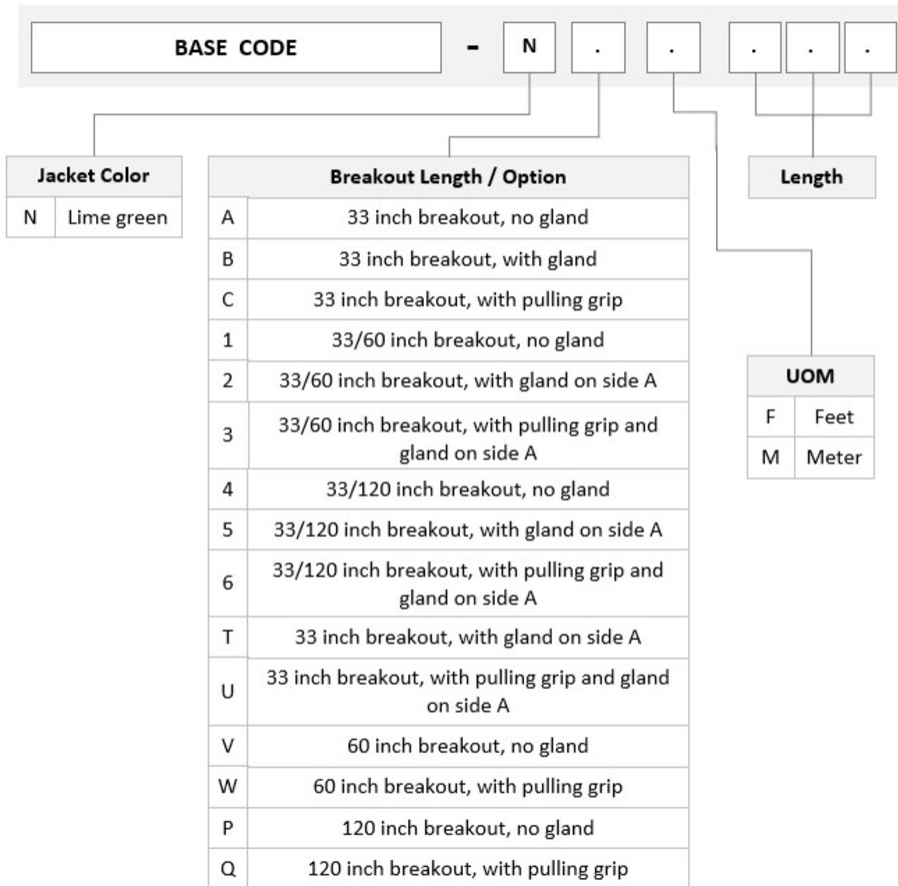

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0° | 4.40 lb @ 90°

Optical Specifications

Fiber Mode Multimode

Fiber Type OM5, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

FJVMMPAH

Environmental Space

Dual Rated LSZH/Riser | Indoor

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



Included Products

- | | | |
|----------------------------------|---|--|
| 760229070
N-048-MP-5G-F12LM/D | - | Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 48 fiber multi-unit with 12 fiber subunits, Gel-free, Multimode OM5, Feet jacket marking, Lime green jacket color, Dca flame rating |
| 860647056 | - | MPO12, LOW LOSS, FEMALE, OM5, LIME, 3mm |