


## Base Product

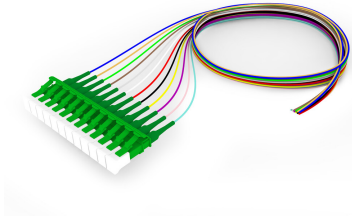

Singlemode LC APC to Unconnectorized, 0.9 mm Tight Buffer Fiber Pigtail, 12-fiber Kit, Blue - Aqua (1-12)

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   Europe   Latin America   Middle East /Africa   North America                              |
| <b>Portfolio</b>             | CommScope®   |
| <b>Product Type</b>          | Fiber pigtail, unjacketed  |
| <b>Product Brand</b>         | SYSTIMAX InstaPATCH® 360   |
| <b>Product Series</b>        | FAW  |
| <b>Ordering Note</b>         | For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications

|                               |        |
|-------------------------------|--------|
| <b>Color, boot A</b>          | Green  |
| <b>Color, connector A</b>     | Green  |
| <b>Interface, Connector A</b> | LC/APC |
| <b>Total Fibers, quantity</b> | 12     |

## Dimensions

|   |        |
|---|--------|
| <b>Cable Assembly Length Range (m)</b>  | 1 – 20 |
| <b>Cable Assembly Length Range (ft)</b> | 1 – 66 |

## Ordering Tree

# FAWLAUCOC



## Mechanical Specifications

**Cable Retention Strength, maximum** 1.00 lb @ 0 ° | 1.00 lb @ 90 °

## Optical Specifications

**Fiber Mode** Singlemode

**Fiber Type** G.652.D | G.657.A1, TeraSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Unrated

## Regulatory Compliance/Certifications

### Agency

CHINA-ROHS

ISO 9001:2015

REACH-SVHC

ROHS

UK-ROHS

### Classification

Below maximum concentration value

Designed, manufactured and/or distributed under this quality management system

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

Compliant

Compliant



## Included Products

- 460125297 – Behind The Wall Pre-Radiused LC APC Connector for 0.9 mm Fiber, single-mode
- X-TB-8W – TeraSPEED® 900µm Tight Buffered Fiber