


# U4XMXLCCAM

## Base Product

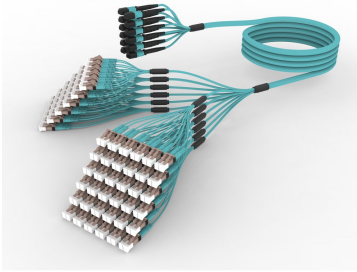

Ultra Low Loss OM4 MPO12 Pinned to LC/UPC 144-Fiber InstaPATCH® 360 Ruggedized Fanout Cable, Low Smoke Zero Halogen

This product will be discontinued on: April 30, 2024

### Replaced By:

U4XMXLCCM

Ultra Low Loss ULL LazrSPEED® 550 MPO(Pinned) to LC/UPC Ruggedized fanout Cable, 144-Fiber, LSZH, 12 fiber PmP 2.0 mm /B2ca

## Product Classification

<b>Regional Availability</b>	Europe
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Ruggedized fanout
<b>Product Brand</b>	SYSTIMAX InstaPATCH® 360   SYSTIMAX ULL
<b>Ordering Note</b>	For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration   Not available in the United States or Canada

## General Specifications

<b>Color, boot A</b>	Black
<b>Color, connector A</b>	Aqua
<b>Color, boot B</b>	Aqua
<b>Color, connector B</b>	Beige
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Aqua
<b>Interface, Connector A</b>	MPO-12/UPC Male
<b>Interface, Connector B</b>	LC/UPC
<b>Jacket Color</b>	Aqua
<b>Polarity</b>	Method B Enhanced (ULL)


# U4XMXLCAM

<b>Fibers per Subunit, quantity</b>	12
<b>Total Fibers, quantity</b>	144

## Dimensions

<b>Cable Assembly Length Range (m)</b>	3 – 999
<b>Cable Assembly Length Range (ft)</b>	7 – 999

## Ordering Tree

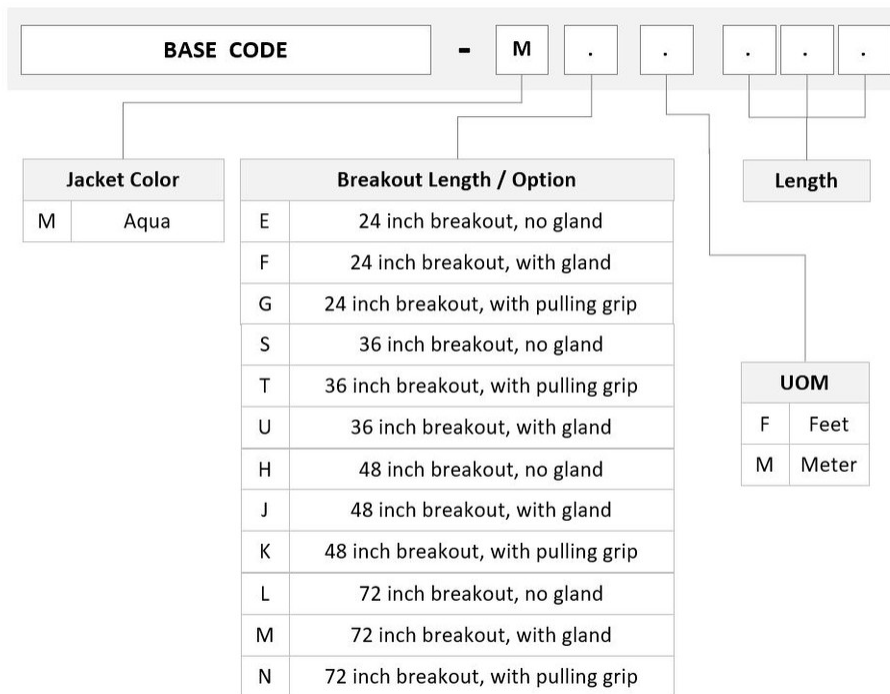

## Optical Specifications

<b>Fiber Mode</b>	Multimode
<b>Fiber Type</b>	OM4, LazrSPEED®

## Environmental Specifications

<b>Operating Temperature</b>	-10 °C to +60 °C (+14 °F to +140 °F)
<b>Environmental Space</b>	Indoor   Low Smoke Zero Halogen (LSZH)

## Regulatory Compliance/Certifications

# U4XMXLCAM

---

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant



## Included Products

760239604 N-144-MP-5K-F12AQ/B2	- Fiber Indoor Cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 144 fiber, 12 fiber subunits, Multimode OM4, Gel-free, Feet jacket marking, Aqua jacket color, B2ca flame rating
860366228	- MPO12, ULTRA LOW LOSS, MALE, OM3/4, AQUA, 3mm
860637378	- LazrSPEED® Elite LC Connector duplex for 1.6 mm Fiber, multimode
CS-5K-MP	- LazrSPEED® 550 OM4 Bend-Insensitive Multimode Fiber