


UJGQPQXBM

Base Product

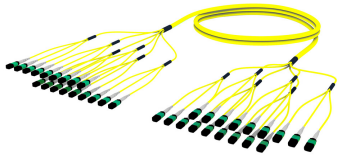

Ultra Low Loss (ULL) Singlemode MPO QSFP (Unpinned) to MPO QSFP (Pinned), Pre-terminated Trunk Cable, MPO8, 144-Fiber, Low Smoke Zero Halogen (LSZH)/Riser

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Gray
Color, connector A	Green
Color, boot B	Gray
Color, connector B	Green
Construction Type	Stranded
Furcation Color	Yellow
Interface, Connector A	MPO-08/APC Female
Interface Feature, connector A	QSFP configuration
Interface, Connector B	MPO-08/APC Male
Interface Feature, connector B	QSFP configuration
Jacket Color	Yellow
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	24
Total Fibers, quantity	144


Dimensions

Breakout Length	33 in
------------------------	-------

UJGQPQXBM

Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

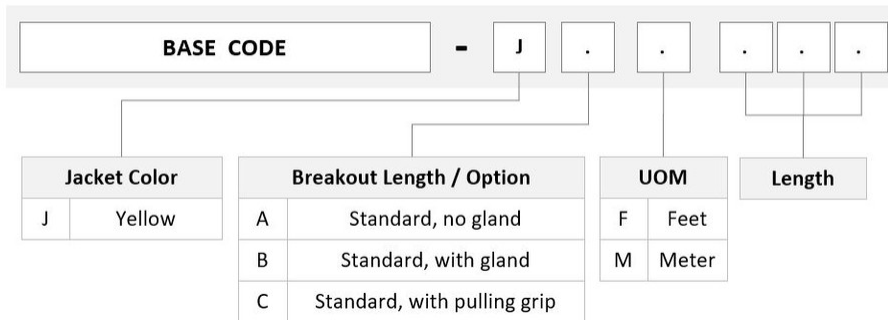

Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 ° 4.40 lb @ 90 °
--	---------------------------------

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Dual Rated LSZH/Riser Indoor

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



UJGQPQXBM

Included Products

- 760240266
N-144-MP-8G-F24YL/D – Low Smoke Zero Halogen Riser MPO Trunk Cable, 144 fiber multi-unit with 24 fiber subunits
- 860637705 – MPO8, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 3mm
- 860637706 – MPO8, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm