


# ULGSASACM

## Base Product

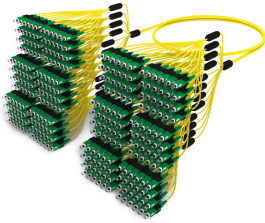

Ultra Low Loss ULL TeraSPEED® SC/APC to SC/APC Ruggedized fanout Cable, 144-Fiber, Plenum, 12 fiber PmP 2.0 mm Dca

## Product Classification

### Regional Availability

Asia | Australia/New Zealand | Europe | Latin America | Middle East/Africa | North America

### Portfolio

CommScope®

### Product Type

Ruggedized fanout

### Product Brand

SYSTIMAX ULL

### Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

## General Specifications

|                                       |          |
|---------------------------------------|----------|
| <b>Color, boot A</b>                  | Green    |
| <b>Color, connector A</b>             | Green    |
| <b>Color, boot B</b>                  | Green    |
| <b>Color, connector B</b>             | Green    |
| <b>Construction Type</b>              | Stranded |
| <b>Furcation Color</b>                | Yellow   |
| <b>Interface, Connector A</b>         | SC/APC   |
| <b>Interface Feature, connector A</b> | ULL      |
| <b>Interface, Connector B</b>         | SC/APC   |
| <b>Interface Feature, connector B</b> | ULL      |
| <b>Jacket Color</b>                   | Yellow   |
| <b>Fibers per Subunit, quantity</b>   | 12       |
| <b>Total Fibers, quantity</b>         | 144      |

## Dimensions

|   |          |
|---|----------|
| <b>Cable Assembly Length Range (m)</b>  | 3 – 305  |
| <b>Cable Assembly Length Range (ft)</b> | 10 – 999 |

# ULGSASACM

## Ordering Tree



## Optical Specifications

|                   |                      |
|-------------------|----------------------|
| <b>Fiber Mode</b> | Singlemode           |
| <b>Fiber Type</b> | G.657.A2, TeraSPEED® |

## Environmental Specifications

|   |                                      |
|---|--------------------------------------|
| <b>Operating Temperature</b>                        | -10 °C to +60 °C (+14 °F to +140 °F) |
| <b>EN50575 CPR Cable EuroClass Fire Performance</b> | Dca                                  |
| <b>Environmental Space</b>                          | Indoor   Plenum                      |

## Regulatory Compliance/Certifications

| Agency        | Classification   |
|---------------|--|
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |

# ULGSASACM

---

## Included Products

- 760242061  
P-144-MP-8G-F12YL/20T – Fiber Indoor Cable, Plenum MPO Trunk, 144 fiber multi-unit with 12 fiber subunits, Singlemode G.657.A2/B2, Gel-free, Feet jacket marking, Yellow jacket color