


# A3XMXMPAH

Base Product

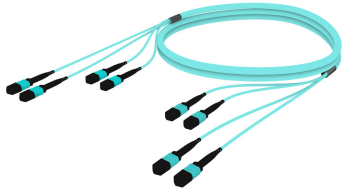

OM4 MPO12 (Pinned) to MPO12 (Unpinned), Fiber Trunk Cable Assembly, 48-Fiber, B2ca, Method A, Low Smoke Zero Halogen

## OBSOLETE

This product was discontinued on: April 30, 2024

### Replaced By:

A3XMXMPCH

OM4 MPO12 (Pinned) to MPO12 (Unpinned), Fiber Trunk Cable Assembly, 48-Fiber, B2ca, Method A, Low Smoke Zero Halogen

## Product Classification

<b>Regional Availability</b>	Europe
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber trunk cable assembly
<b>Ordering Note</b>	For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

<b>Color, boot A</b>	Black
<b>Color, connector A</b>	Aqua
<b>Color, boot B</b>	Black
<b>Color, connector B</b>	Aqua
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Aqua
<b>Interface, Connector A</b>	MPO-12/UPC Male
<b>Interface, Connector B</b>	MPO-12/UPC Female
<b>Jacket Color</b>	Aqua
<b>Polarity</b>	Method A
<b>Fibers per Subunit, quantity</b>	12
<b>Total Fibers, quantity</b>	48


# A3XMXMPAH

## Dimensions

**Cable Assembly Length Range (m)** 3 – 999

**Cable Assembly Length Range (ft)** 10 – 999

## Ordering Tree

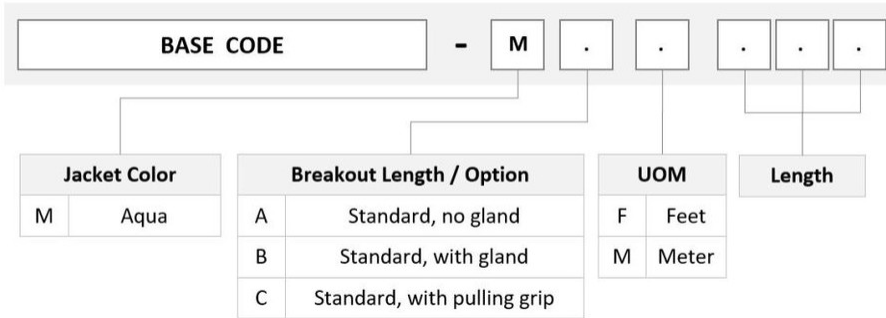

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0° | 4.40 lb @ 90°

## Optical Specifications

**Fiber Mode** Multimode

**Fiber Type** OM4, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**EN50575 CPR Cable EuroClass Fire Performance** B2ca

**Environmental Space** Indoor | Low Smoke Zero Halogen (LSZH)

## Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

# A3XMXMPAH

---



## Included Products

- 760239601  
N-048-MP-5K-F12AQ/B2 – Fiber indoor cable, LazrSPEED®, Low Smoke Zero Halogen Riser MPO Trunk, 48 fibers, 12 fiber subunits, Multimode OM4, Gel-free, Feet jacket marking, Aqua jacket color, B2ca Flame rating
- 860366210 – MPO12, ULTRA LOW LOSS, FEMALE, OM3/4, AQUA, 3mm
- 860366228 – MPO12, ULTRA LOW LOSS, MALE, OM3/4, AQUA, 3mm