


# AGGMPMXCF

## Base Product

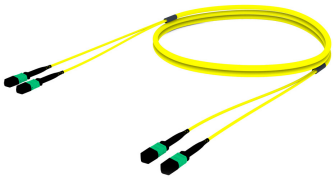

Ultra Low Loss ULL TeraSPEED® MPO(Unpinned) to MPO(Pinned) Pre-terminated Trunk Cable, MPO12, 24-Fiber, Plenum, 12 fiber PmP 2.0 mm Dca, Method A

## Product Classification

### Regional Availability

Asia | Australia/New Zealand | Europe | Latin America | Middle East/Africa | North America

### Portfolio

CommScope®

### Product Type

Fiber trunk cable assembly

### Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

## General Specifications

### Color, boot A

Black

### Color, connector A

Green

### Color, boot B

Black

### Color, connector B

Green

### Construction Type

Stranded

### Furcation Color

Yellow

### Interface, Connector A

MPO-12/APC Female

### Interface, Connector B

MPO-12/APC Male

### Jacket Color

Yellow

### Polarity

Method A

### Fibers per Subunit, quantity

12

### Total Fibers, quantity

24

## Dimensions

### Breakout Length

33 in

### Cable Assembly Length Range (m)


3 – 999

### Cable Assembly Length Range (ft)

10 – 999

# AGGMPMXCF

## Ordering Tree

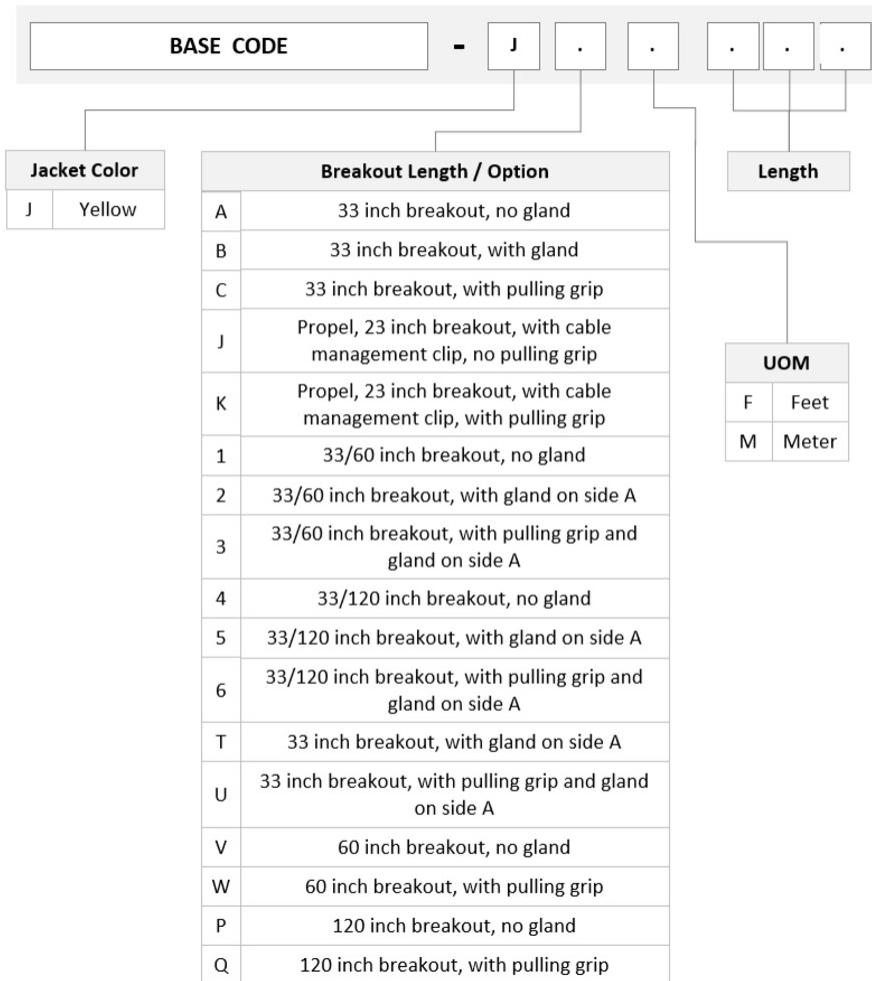

## Optical Specifications

**Fiber Mode**

Singlemode

**Fiber Type**

G.657.A2, TeraSPEED®

## Environmental Specifications

**Operating Temperature**

-10 °C to +60 °C (+14 °F to +140 °F)

**EN50575 CPR Cable EuroClass Fire Performance**

Dca

**Environmental Space**

Indoor | Plenum

## Regulatory Compliance/Certifications

# AGGMPMXCF

---

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



## Included Products

760242051 P-024-MP-8G-F12YL/20T	- Fiber indoor cable, Plenum for MPO Trunks, 24 fiber with 12 fiber subunits, Singlemode G.657. A2/B2, Feet jacket marking, Yellow jacket color
860659010	- MPO-12, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 2mm
860659016	- MPO12, ULL, FEMALE, SM, GREEN, 2MM