


FNWSCSCAF

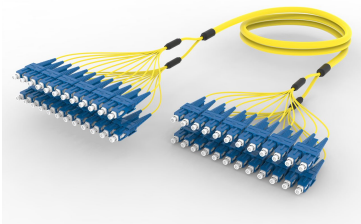

Singlemode SC/UPC to SC/UPC 24-Fiber InstaPATCH® 360 Ruggedized Fanout Cable, Low Smoke Zero Halogen

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Ruggedized fanout
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration Not available in the United States or Canada


General Specifications

Color, boot A	Blue
Color, connector A	Blue
Color, boot B	Blue
Color, connector B	Blue
Construction Type	Stranded
Furcation Color	Yellow
Interface, Connector A	SC/UPC
Interface, Connector B	SC/UPC
Jacket Color	Yellow
Fibers per Subunit, quantity	12
Total Fibers, quantity	24

Dimensions

Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	8 – 999

 Ordering Tree



Breakout Length / Option	
E	24 inch breakout, no gland
F	24 inch breakout, with gland
S	36 inch breakout, no gland
U	36 inch breakout, with gland
H	48 inch breakout, no gland
J	48 inch breakout, with gland
L	72 inch breakout, no gland
M	72 inch breakout, with gland
P	96 inch breakout, no gland
Q	96 inch breakout, with gland

Length

UOM	
F	Feet
M	Meter

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

COMMScope®

FNWSCSCAF

UK-ROHS

Compliant



Included Products

- | | | |
|---------------------|---|---|
| 460125768 | - | TeraSPEED® Pre-Radiused SC Connector for 1.6 mm Fiber Cordage, Duplex, Singlemode |
| 760050351 | - | Fiber indoor cable, TeraSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 24 fiber with 12 fiber subunits, Gel-free, Singlemode G.652.D and G.657.A1, Feet jacket marking, Yellow jacket color, Dca flame rating |
| N-024-MP-8W-F12YL/D | | |