


AGXMPMPCL

Base Product

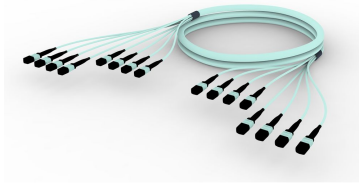

Ultra Low Loss ULL LazrSPEED® 550 MPO(Unpinned) to MPO (Unpinned) Pre-terminated Trunk Cable, MPO12, 96-Fiber, Plenum, 12 fiber PmP 2.0 mm Dca, Method A

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Black
Color, connector A	Black
Color, boot B	Black
Color, connector B	Black
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-12/UPC Female
Interface, Connector B	MPO-12/UPC Female
Jacket Color	Aqua
Polarity	Method A
Fibers per Subunit, quantity	12
Total Fibers, quantity	96

Dimensions


Breakout Length	33 in
------------------------	-------

AGXMPMPCL

Cable Assembly Length Range (m) 3 – 999

Cable Assembly Length Range (ft) 10 – 999

Ordering Tree

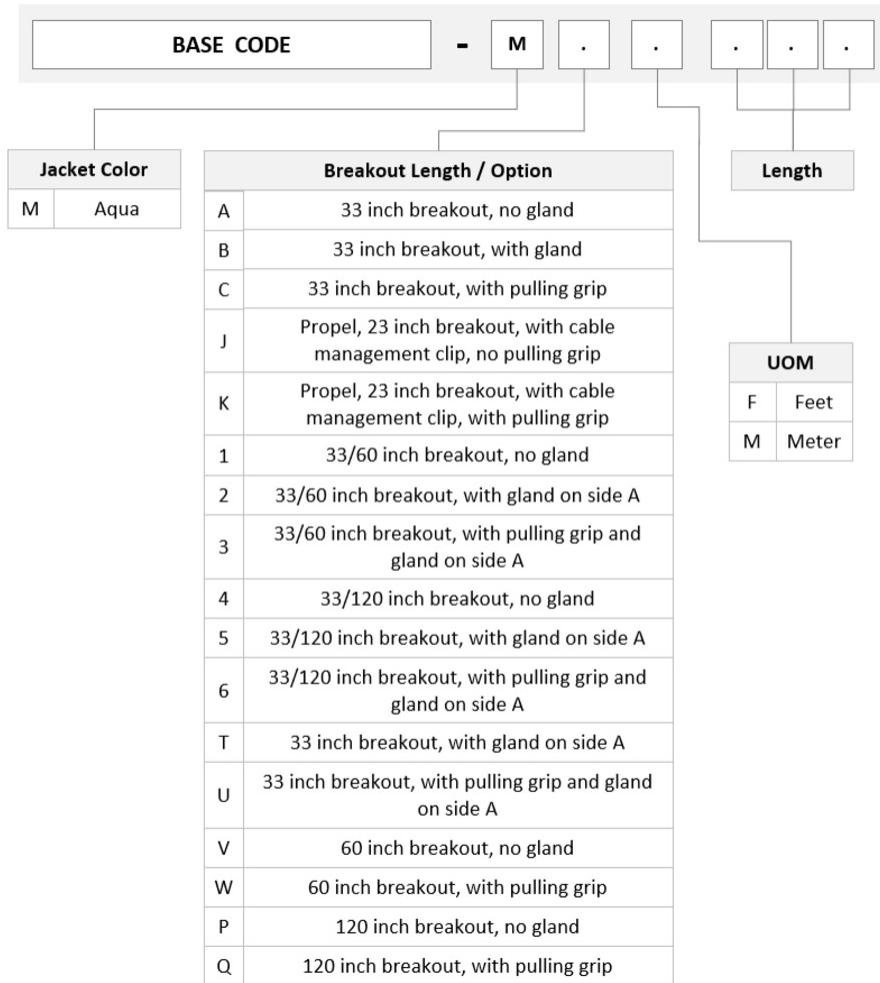

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

EN50575 CPR Cable EuroClass Fire Performance Dca

AGXMPMPCL

Environmental Space

Indoor | Plenum

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



Included Products

- 760242122
P-096-MP-5K-F12AQ/20T – Fiber indoor cable, LazrSPEED® Plenum MPO Trunk, 96 fiber multi-unit with 12 fiber subunits, Multimode OM4, Gel-free, Feet jacket marking, Aqua jacket color
- 860659012 – MPO12, ULL, FEMALE, OM3/4, AQUA, 2MM