


# AJXMXMPAG

---

## Base Product

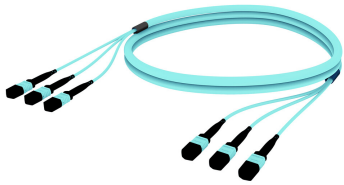

OM4 MPO12 (Pinned) to MPO12 (Unpinned), Fiber Trunk Cable Assembly, 36-Fiber, Method A, Low Smoke Zero Halogen

## Product Classification

### Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

### Portfolio

CommScope®

### Product Type

Fiber trunk cable assembly

### Ordering Note

For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

## General Specifications

### Color, boot A

Black

### Color, connector A

Aqua

### Color, boot B

Black

### Color, connector B

Aqua

### Construction Type

Stranded

### Furcation Color

Aqua

### Interface, Connector A

MPO-12/UPC Male

### Interface, Connector B

MPO-12/UPC Female

### Jacket Color

Aqua

### Polarity

Method A

### Fibers per Subunit, quantity

12

### Total Fibers, quantity

36

## Dimensions

### Cable Assembly Length Range (m)

3 – 999

### Cable Assembly Length Range (ft)

10 – 999

## Ordering Tree



# AJXMXMPAG

---

- 860366210 – MPO12, ULTRA LOW LOSS, FEMALE, OM3/4, AQUA, 3mm
- 860366228 – MPO12, ULTRA LOW LOSS, MALE, OM3/4, AQUA, 3mm