


DFT-48SM-121

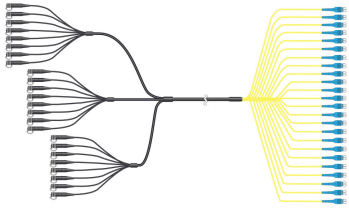

HELIAX® Direct, 48 single mode fiber, 7 mm cable. End 1: Outdoor fiber connectors compatible with ODC interface, End 2: DLC

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Wireless Fiber Cable Assemblies
Product Brand	HELIAX®
Product Series	DFT
Ordering Note	CommScope® non-standard product

General Specifications


Construction Type	Discrete fiber trunk
Interface, Connector A	ODC-LC
Interface Feature, connector A	Outdoor
Interface Body Style, connector A	Straight
Interface, Connector B	DLC
Interface Body Style, connector B	Straight
Jacket Color	Black
Total Fibers, quantity	48

Dimensions

Cable Assembly Length Range (ft)	5 – 400
Diameter Over Jacket	10.3 mm 0.406 in

Ordering Tree

DFT-48SM-121-10

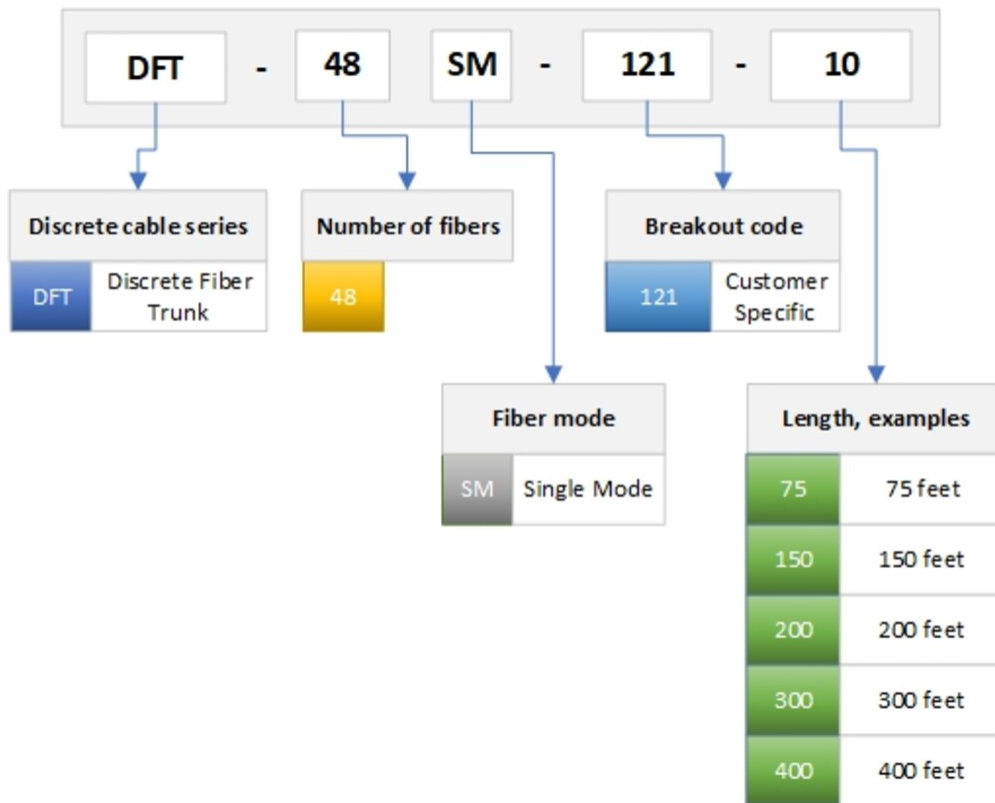

Mechanical Specifications

Minimum Bend Radius 103 mm | 4.055 in
Minimum Bend Radius, furcation 30 mm | 1.181 in

Optical Specifications

Fiber Type G.657.A2
Insertion Loss, typical note Insertion loss is measured at 1310 and 1550 nm
Insertion Loss, typical 0.75

Environmental Specifications

Operating Temperature -40 °C to +75 °C (-40 °F to +167 °F)
Environmental Space Outdoor

Packaging and Weights

Cable weight 136 kg/km | 91.388 lb/kft

DFT-48SM-121

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



* Footnotes

Insertion Loss, typical note Insertion loss is measured at a room temp of +20°C (+68°F)