


FEWL6SC21

Base Product

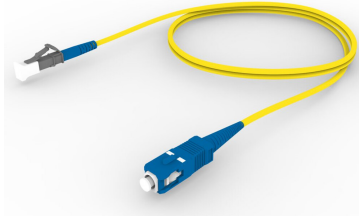

Singlemode LC/UPC Keyed Slate to SC/UPC Fiber Patch Cord, 1.6 mm Simplex, Riser

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber patch cord, simplex
Product Brand	SYSTIMAX InstaPATCH® 360
Product Series	FEW
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	1
Color, boot A	Blue
Color, connector A	Slate
Connector B, quantity	1
Color, boot B	Blue
Color, connector B	Blue
Interface, Connector A	LC/UPC
Interface Feature, connector A	Keyed
Interface, Connector B	SC/UPC
Jacket Color	Yellow
Polarity	Method B
Total Fibers, quantity	1

Dimensions


Cable Assembly Length Range (m)	1 – 999
Cable Assembly Length Range (ft)	1 – 999

FEWL6SC21

Diameter Over Jacket

1.6 mm | 0.063 in

Ordering Tree

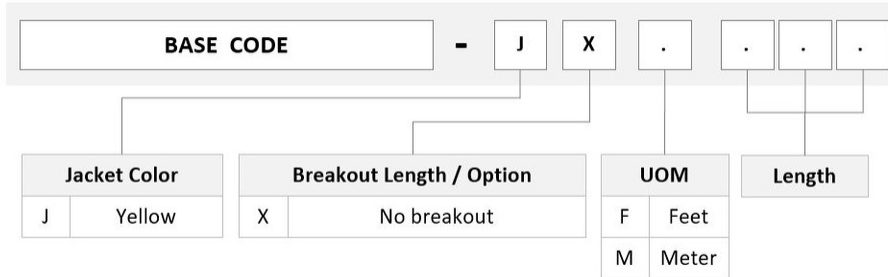

Mechanical Specifications

Cable Retention Strength, maximum

11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode

Singlemode

Fiber Type

G.652.D | G.657.A1, TeraSPEED®

Environmental Specifications

Operating Temperature

-10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space

Riser

Regulatory Compliance/Certifications

Agency

ISO 9001:2015

Classification

Designed, manufactured and/or distributed under this quality management system

Included Products

- 460125743 – TeraSPEED® Pre-Radiused SC Connector for 1.6 mm Fiber Cordage, Simplex, Singlemode
- 760102723 – TeraSPEED® Pre-Radiused Keyed LC Connector for 1.6 mm Fiber, simplex Singlemode, slate SFC-LCR-16-KSL
- R-001-SP-8W-F16 – Fiber indoor cable, TeraSPEED® 1.6mm Riser Simplex , 1 fiber, Singlemode G.652.D and G.657.A1, Feet jacket marking