


Singlemode LC APC to LC APC, Fiber Patch Cord, 1.6 mm Simplex, Riser

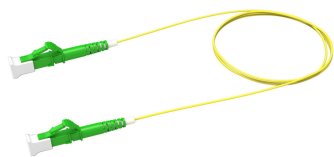

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber patch cord, simplex
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Color, boot A	Green
Color, boot B	Green
Color, connector A	Green
Color, connector B	Green
Interface, Connector A	LC/APC
Interface, Connector B	LC/APC
Jacket Color	Yellow
Polarity	Method B
Total Fibers, quantity	1

Dimensions

Cable Assembly Length, minimum (ft)	2
Cable Assembly Length, maximum (ft)	325
Cable Assembly Length, minimum (m)	1
Cable Assembly Length, maximum (m)	99
Diameter Over Jacket	1.6 mm 0.063 in

FEWLALA21

Ordering Tree

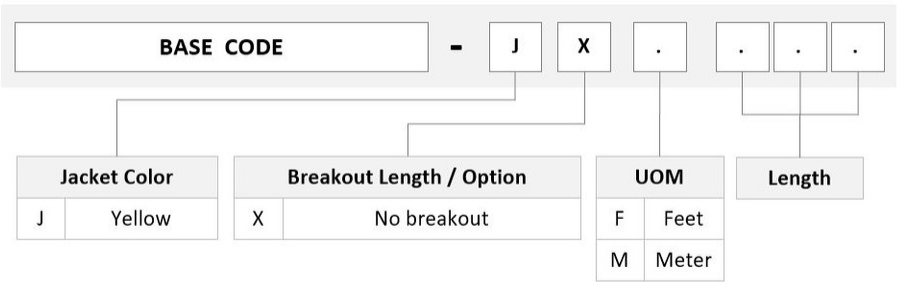

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Singlemode

Fiber Type G.652.D | G.657.A1, TeraSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Riser

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

ISO 9001:2015

REACH-SVHC

ROHS

Classification

Below maximum concentration value

Designed, manufactured and/or distributed under this quality management system

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant



Included Products

- 760004515 – TeraSPEED® 1.6 mm Riser Simplex Cable
- R-001-SP-8W-F16YL
- 860637445 – LC/APC Connector, Single-mode, Green