


# 3-2105032-0

---

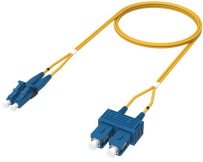

Fiber Optic Patch Cord, OS2, LC/SC duplex, 1.8 mm LSZH & OFNR, 30 m

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   China   Europe   India   Middle East/Africa
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber patch cord, duplex
<b>Product Series</b>	210

## General Specifications

 
<b>Connector A, quantity</b>	2
<b>Color, boot A</b>	Blue
<b>Color, connector A</b>	Blue
<b>Connector B, quantity</b>	2
<b>Color, boot B</b>	Blue
<b>Color, connector B</b>	Blue
<b>Interface, Connector A</b>	LC/UPC
<b>Interface, Connector B</b>	SC/UPC
<b>Jacket Color</b>	Yellow
<b>Polarity</b>	Pairs, flipped
<b>Total Fibers, quantity</b>	2

## Dimensions

<b>Cord Length</b>	30 m   98.425 ft
<b>Diameter Over Jacket</b>	1.8 mm   0.071 in

## Ordering Tree

# 3-2105032-0



Examples of Lengths (meters)	
-5	5 meters
1- -0	10 meters
1- -5	15 meters
7- -5	75 meters
8- -0	80 meters
9- -y	Specific length

## Optical Specifications

<b>Fiber Mode</b>	Singlemode
<b>Fiber Type</b>	OS2
<b>Insertion Loss, maximum, connector A</b>	0.3 dB
<b>Insertion Loss, maximum, connector B</b>	0.5 dB
<b>Return Loss, minimum, connector A</b>	50 dB
<b>Return Loss, minimum, connector B</b>	50 dB

## Environmental Specifications

<b>Environmental Space</b>	Dual Rated LSZH/Riser
----------------------------	-----------------------

## Packaging and Weights

<b>Packaging quantity</b>	1
---------------------------	---

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



