


FPCMY-SPLC-P-4M

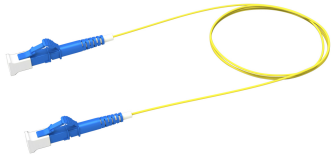

Fiber Optic Patch Cord, Simplex, Singlemode, LC/UPC to LC/UPC, yellow, 4 m

Product Classification

Regional Availability	Latin America North America
Product Type	Fiber patch cord, simplex
Product Series	FPCMY

General Specifications

Connector A, quantity	1
Color, boot A	Blue
Color, connector A	Blue
Connector B, quantity	1
Color, boot B	Blue
Color, connector B	Blue
Interface, Connector A	LC/UPC
Interface, Connector B	LC/UPC
Jacket Color	Yellow
Total Fibers, quantity	1

Dimensions

Cord Length	4 m 13.123 ft
Diameter Over Jacket	1.7 mm 0.067 in

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2, TeraSPEED®
Insertion Loss, maximum, connector A	0.3 dB
Insertion Loss, maximum, connector B	0.3 dB
Return Loss, minimum, connector A	55 dB
Return Loss, minimum, connector B	55 dB

FPCMY-SPLC-P-4M

Environmental Specifications

Environmental Space Plenum

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

