

Fiber Optic Duplex Adapter, Multimode LC/UPC, OM3/OM4, aqua, with flanges

- High quality zirconia ceramic split sleeves ensuring high precision alignment, reliability and improved reconnect ability
- Translucent easy grip dust cap and integrated mounting clips
- High quality one piece housing, no ultrasonic welding

**OBSOLETE**

This product was discontinued on: June 1, 2022


Product Classification

Regional Availability	Asia   Australia/New Zealand   EMEA   Latin America   North America
Product Type	Fiber adapter
Product Series	OC-ADP

General Specifications

Body Style	Duplex
Color	Aqua
Interface	LC/UPC
Mounting	Square flange
Total Ports, quantity	2
Transmission Standards	IEC 60754-1   IEC 61300-3-42

Outline Drawing

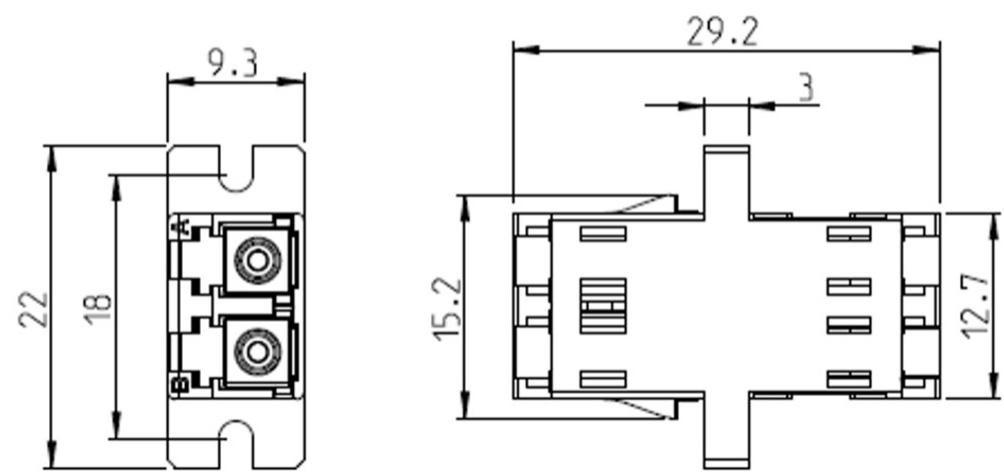

Material Specifications

Alignment Sleeve Material      Ceramic

Mechanical Specifications

Coupling Retention Force      70 N | 15.737 lbf

Optical Specifications

Fiber Mode      Multimode

Insertion Loss, maximum      0.1 dB

Environmental Specifications

Operating Temperature      -40 °C to +70 °C (-40 °F to +158 °F)

Packaging and Weights

Packaging quantity      1

Packaging Type      Bag

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant

UK-ROHS

Compliant

