


## EHD Multimode OM5, 24 port LC field term splice cassette

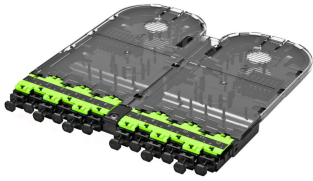

### Product Classification

<b>Regional Availability</b>	North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber cassette
<b>Product Series</b>	EHD

### General Specifications

<b>Color, front</b>	Lime green
<b>Interface, front</b>	LC/UPC
<b>Interface, rear</b>	No pigtail
<b>Total Fibers, quantity</b>	24

### Dimensions

<b>Height</b>	11.43 mm   0.45 in
<b>Width</b>	169.672 mm   6.68 in
<b>Depth</b>	163.83 mm   6.45 in

### Optical Specifications

<b>Fiber Mode</b>	Multimode
-------------------	-----------

### Environmental Specifications

<b>Safety Standard</b>	CE   CSA   UL
------------------------	---------------

### Packaging and Weights

<b>Packaging quantity</b>	1
---------------------------	---

**Weight, net**

0.159 kg | 0.35 lb

### Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

