


EH1457-002 | LC DUPLEX ADAPTER, W/ FLANGE, AQUA, W/P

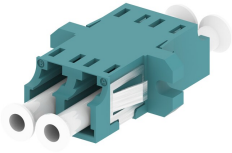

Fiber Optic Duplex Adapter, Multimode LC/UPC, Aqua, with flanges

Product Classification

Regional Availability Asia | EMEA | Latin America | North America

Product Type Fiber adapter

General Specifications

Body Style Duplex

Color Aqua

Interface LC/UPC

Mounting Flange

Shuttered No

Total Ports, quantity 2

Transmission Standards IEC 60754-1 | IEC 61300-3-42

Dimensions

Width 15.4 mm | 0.606 in

Length 29.2 mm | 1.15 in

Material Specifications

Alignment Sleeve Material Zirconia

Optical Specifications

Fiber Mode Multimode

Insertion Loss, maximum 0.2 dB

Environmental Specifications

Installation temperature -40 °C to +70 °C (-40 °F to +158 °F)

Flammability Rating UL 94 V-0

EH1457-002 | LC DUPLEX ADAPTER, W/ FLANGE, AQUA, W/P

Packaging and Weights

Included	Dust caps
Packaging Type	Bag

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant

