


# FGS-DDSP-B

---

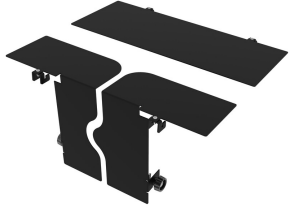

FiberGuide® Split Cover for Downspout, 4x6in, Black

## Product Classification

|                              |                                                                     |
|------------------------------|---------------------------------------------------------------------|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   EMEA   Latin America   North America |
| <b>Portfolio</b>             | CommScope®                                                          |
| <b>Product Type</b>          | Fiber raceway cover                                                 |
| <b>Product Brand</b>         | FiberGuide®                                                         |
| <b>Product Series</b>        | FGS                                                                 |

## General Specifications

|                     |            |
|---------------------|------------|
| <b>Color</b>        | Black      |
| <b>Orientation</b>  | Horizontal |
| <b>Section Type</b> | Downspout  |

## Dimensions

|                          |                               |
|--------------------------|-------------------------------|
| <b>Height</b>            | 50.8 mm   2 in                |
| <b>Width</b>             | 152.4 mm   6 in               |
| <b>System Dimensions</b> | 102 mm x 152 mm (4 in x 6 in) |

## Material Specifications

|                      |                           |
|----------------------|---------------------------|
| <b>Material Type</b> | Engineering Thermoplastic |
|----------------------|---------------------------|

## Environmental Specifications

|                                |                                |
|--------------------------------|--------------------------------|
| <b>Flammability Rating</b>     | CSA S143   UL 2024   UL 94 V-0 |
| <b>Halogen Characteristics</b> | Blue Angel   TCO '99   WEEE    |
| <b>Safety Standard</b>         | CSA   UL                       |

## Packaging and Weights

|                    |                     |
|--------------------|---------------------|
| <b>Weight, net</b> | 4.226 kg   9.317 lb |
|--------------------|---------------------|

# FGS-DDSP-B

---

## Regulatory Compliance/Certifications

| <b>Agency</b> | <b>Classification</b>                                                                                                          |
|---------------|--------------------------------------------------------------------------------------------------------------------------------|
| CHINA-ROHS    | Below maximum concentration value                                                                                              |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant                                                                                                                      |
| UK-ROHS       | Compliant                                                                                                                      |

