


FGS-MSHS-K

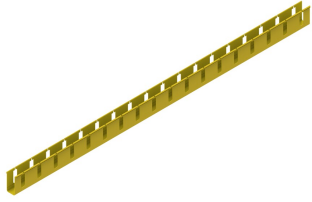

FiberGuide® Vertical Straight Section with 2in Slot Spacing, 2x4in, Yellow

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Slotted vertical
Product Brand	FiberGuide®
Product Series	FGS

General Specifications

Product Feature	Slotted
Color	Yellow
Orientation	Vertical
Section Type	Straight section

Dimensions

Height	50.8 mm 2 in
Width	101.6 mm 4 in
Length	1829 mm 72.008 in
System Dimensions	51 mm x 102 mm (2 in x 4 in)

Material Specifications

Material Type	Engineering Thermoplastic
----------------------	---------------------------

Environmental Specifications

Flammability Rating	CSA S143 UL 2024 UL 94 V-0
Halogen Characteristics	Blue Angel TCO '99 WEEE
Safety Standard	CSA UL

Packaging and Weights

FGS-MSHS-K

Weight, net

3.725 kg | 8.212 lb

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Below maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

