


# 294686

---

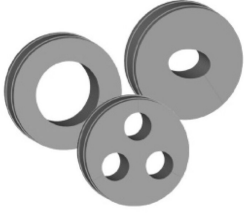

4 in boot cushion insert with 3 holes for 1/2 in corrugated coaxial cable

## Product Classification

|                      |                              |
|----------------------|------------------------------|
| <b>Product Type</b>  | Cushion insert               |
| <b>Product Brand</b> | I-Line                       |
| <b>Ordering Note</b> | ANDREW® non-standard product |

## General Specifications

|                           |            |
|---------------------------|------------|
| <b>Cable Type</b>         | Corrugated |
| <b>Cables per Cushion</b> | 3          |
| <b>Color</b>              | Black      |

## Dimensions

|                     |                    |
|---------------------|--------------------|
| <b>Height</b>       | 82.55 mm   3.25 in |
| <b>Length</b>       | 25.4 mm   1 in     |
| <b>Nominal Size</b> | 1/2 in             |

## Material Specifications

|                      |             |
|----------------------|-------------|
| <b>Material Type</b> | EPDM rubber |
|----------------------|-------------|

## Environmental Specifications

|   |  |
|---|--|
| <b>UV Resistance Test Method</b>                  | MIL-STD-810E, Procedure 11, Method 505 |
| <b>UV Resistance, minimum with no degradation</b> | ≥1000 hours                            |
| <b>Weather Resistance Test Method</b>             | 04AS00-03.9.0   IEC 60529:2001, IP66   |

## Packaging and Weights

|                       |                    |
|-----------------------|--------------------|
| <b>Height, packed</b> | 170.18 mm   6.7 in |
| <b>Width, packed</b>  | 129.54 mm   5.1 in |
| <b>Length, packed</b> | 99.06 mm   3.9 in  |
| <b>Included</b>       | Cushion            |

# 294686

---

**Packaging quantity** 1  
**Weight, gross** 0.8 kg | 1.764 lb

## Regulatory Compliance/Certifications

| <b>Agency</b> | <b>Classification</b>  |
|---------------|--|
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.andrew.com/ProductCompliance">www.andrew.com/ProductCompliance</a> |
| ROHS          | Compliant  |
| UK-ROHS       | Compliant  |