


# NG4-MMDKEOLOOB

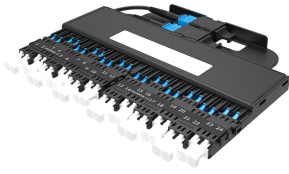

NG4access® MPO Module, singlemode, LC/UPC-MPO 2 – 1x12 fiber, Polarity B, left exit (for MPO module)

- Offers the same craft-friendly interface for LC and SC connectors as the cabled module
- Allow installers to connect an MPO trunk cable to turn up services in rapid installation applications

## Product Classification

<b>Regional Availability</b>	Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber module
<b>Product Brand</b>	NG4access®
<b>Product Series</b>	NG4

## General Specifications

<b>Functionality</b>	Breakout
<b>Application</b>	NG4 MPO module
<b>Adapter Color</b>	Blue
<b>Adapters, quantity, front</b>	12
<b>Body Style</b>	Duplex
<b>Color, front</b>	Black
<b>Color, housing</b>	Black
<b>Color, rear</b>	Black
<b>Interface, front</b>	LC/UPC
<b>Interface, rear</b>	MPO
<b>Interface Feature, rear</b>	Standard
<b>Polarity</b>	Method B Enhanced
<b>Total Fibers, quantity</b>	24
<b>Total Ports, quantity, front</b>	24

## Dimensions

<b>Height</b>	13.21 mm   0.52 in
<b>Width</b>	159.77 mm   6.29 in

# NG4-MMDKEOLOOB

**Depth** 122.68 mm | 4.83 in

## Outline Drawing



## Optical Specifications

**Fiber Mode** Singlemode  
**Fiber Type** G.657.A2

## Environmental Specifications

**Operating Temperature** -5 °C to +40 °C (+23 °F to +104 °F)  
**Storage Temperature** -5 °C to +50 °C (+23 °F to +122 °F)  
**Relative Humidity** Up to 85%, non-condensing

## Packaging and Weights

**Packaging quantity** 1  
**Packaging Type** Bag | Carton

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>

# NG4-MMDKEOLOOB

---

ROHS Compliant/Exempted

UK-ROHS Compliant/Exempted

