


# SS-TB2550

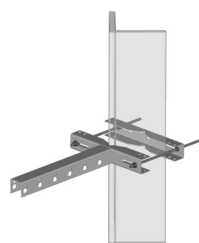

Star Support Tee Bracket for 1-1/2 in to 5-9/16 in OD round members and 2-1/2 in to 5 in angle members

## Product Classification

**Product Type** Support bracket

## General Specifications

**Cable Runs, quantity** 12

**Hole, quantity** 12

**Mounting** Angle members, 63.5–127 mm (2-1/2 in to 5 in) | Round member, 38.1–141.29 mm (1-1/2 in to 5-9/16 in) OD

## Dimensions

**Height** 101.6 mm | 4 in

**Width** 304.8 mm | 12 in

**Length** 254 mm | 10 in

**Mounting Diameter 2, maximum** 127 mm | 5 in

**Mounting Diameter 2, minimum** 63.5 mm | 2.5 in


**Mounting Diameter, maximum** 142.24 mm | 5.6 in

**Mounting Diameter, minimum** 38.1 mm | 1.5 in

**Hole Size** 3/4 in | 7/16 in

# SS-TB2550

## Outline Drawing

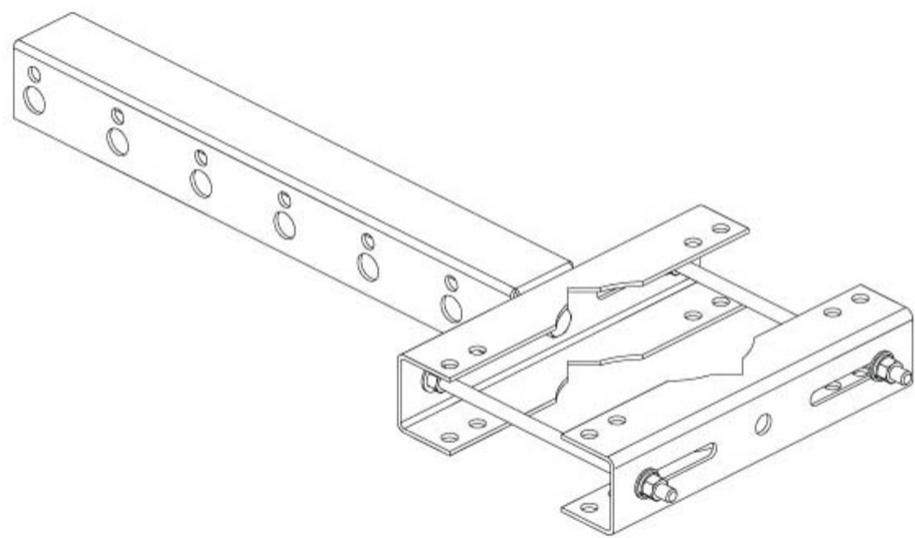

## Material Specifications

<b>Material Type</b>	Hot dip galvanized steel
----------------------	--------------------------

## Packaging and Weights

<b>Included</b>	Brackets
<b>Packaging quantity</b>	1
<b>Weight, net</b>	3.6 kg   7.937 lb

## Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant



# SS-TB2550

---

## Included Products

SS-TB      – Star Support Tee Bracket