


ULGMPLUAD

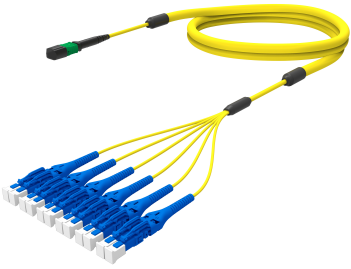

Ultra Low Loss (ULL) Singlemode MPO (Unpinned) to LC/UPC Uniboot, Ruggedized Fanout Cable, 12-Fiber, Plenum

Product Classification

Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Ruggedized fanout

Product Brand

SYSTIMAX ULL

Ordering Note

For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications

Color, boot A

Black

Color, connector A

Green

Color, boot B

Blue

Color, connector B

Blue

Construction Type

Stranded

Furcation Color

Yellow

Interface, Connector A

MPO-12/APC Female

Interface Feature, connector A

Unpinned

Interface, Connector B

LC/UPC

Interface Feature, connector B

Uniboot

Jacket Color

Yellow

Polarity

Method B Enhanced (ULL)

Fibers per Subunit, quantity

12

Total Fibers, quantity

12

Dimensions

Cable Assembly Length Range (m)

3 – 999

ULGMPLUAD

Cable Assembly Length Range (ft) 10 – 999

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Singlemode

Fiber Type G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Plenum

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant



Included Products

- | | | |
|---------------------------------|---|---|
| 760237963
P-012-MP-8G1-F12YL | - | Fiber indoor cable, Plenum for MPO Trunks, 12 fiber, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color |
| 860637435 | - | LC/UPC Connector, Singlemode, Blue, Short Boot |
| 860638318 | - | MPO12, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm |