


1RU-SP3132001 | 1RU SPLTR PNL 1X32 APC/SC

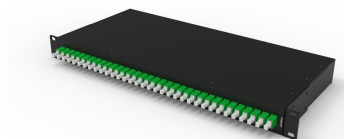

1RU panel, 1X32 split ratio, 1 splitter, SC/APC connectors

Product Classification

Regional Availability	Asia Australia/New Zealand China EMEA India Latin America North America
Product Type	Splitter module
Product Series	1RU

General Specifications

Functionality	Splitting
Technology Type	Planar lightwave circuit (PLC)
Distribution Type	1 x 32 splitter
Interface, Input	SC/APC
Interface, Output	SC/APC
Splitter, quantity	1

Dimensions

Height	43.69 mm 1.72 in
Width	482.6 mm 19 in
Length	199.89 mm 7.87 in

Optical Specifications

Directivity, minimum	55 dB
Polarization Dependent Loss, maximum	0.3 dB
Uniformity, maximum	1.85 dB
Wavelength Range	1260–1650 nm
Insertion Loss, Splitter, maximum	17.5 dB
Return Loss, Splitter, minimum	50 dB

Environmental Specifications

1RU-SP3132001

|

1RU SPLTR PNL 1X32 APC/SC

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Relative Humidity	5%–95%, non-condensing

Packaging and Weights

Packaging quantity	1
--------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant

