

# DFJ-2S5-LCSC2

---



HELIAX® Discrete, 2 single mode fiber, 5 mm LSZH cable. End 1: DLC.  
End 2: SC

## Product Classification

<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Wireless Fiber Cable Assemblies
<b>Product Brand</b>	HELIAX®
<b>Product Series</b>	DFJ

## General Specifications


<b>Connector A, quantity</b>	1
<b>Color, connector A</b>	Blue
<b>Connector B, quantity</b>	2
<b>Color, connector B</b>	Blue
<b>Interface, Connector A</b>	DLC
<b>Interface, Connector B</b>	SC/UPC
<b>Jacket Color</b>	Black

## Dimensions

<b>Breakout Length, connector A</b>	181.864 mm   7.16 in
<b>Breakout Length, connector B</b>	381 mm   15 in
<b>Cable Assembly Length Range (m)</b>	1 – 40

## Ordering Tree

# DFJ-2S5-LCSC2

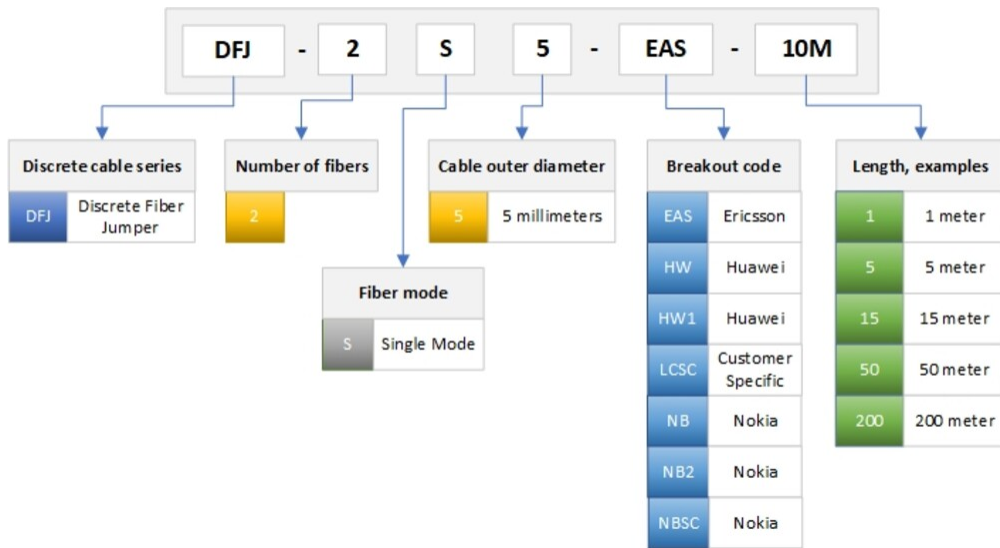

## Optical Specifications

**Fiber Mode** Singlemode  
**Fiber Type** G.657.A2

## Environmental Specifications

**Operating Temperature** -40 °C to +80 °C (-40 °F to +176 °F)  
**Environmental Space** Indoor | Outdoor