


# UNGEMPLUAD

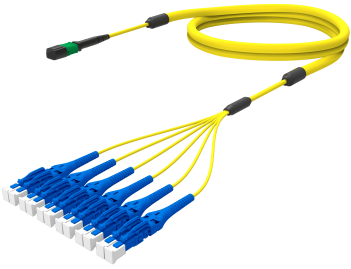

Ultra Low Loss (ULL) Singlemode MPO (Unpinned) to LC/UPC Uniboot, Ruggedized Fanout Cable, 12-Fiber, Low Smoke Zero Halogen

## Product Classification

### Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

### Portfolio

CommScope®

### Product Type

Ruggedized fanout

### Product Brand

SYSTIMAX ULL

### Ordering Note

For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

## General Specifications

### Color, boot A

Black

### Color, connector A

Green

### Color, boot B

Blue

### Color, connector B

Blue

### Construction Type

Stranded

### Furcation Color

Yellow

### Interface, Connector A

MPO-12/APC Female

### Interface Feature, connector A

Unpinned

### Interface, Connector B

LC/UPC

### Interface Feature, connector B

Uniboot

### Jacket Color

Yellow

### Polarity

Method B Enhanced (ULL)

### Fibers per Subunit, quantity

12

### Total Fibers, quantity

12

## Dimensions

### Cable Assembly Length Range (m)

3 – 999

# UNGEMPLUAD

---

**Cable Assembly Length Range (ft)** 10 – 999

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Singlemode

**Fiber Type** G.657.A2, TeraSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Dual Rated LSZH/Riser | Indoor

## Packaging and Weights

**Packaging quantity** 1

## Regulatory Compliance/Certifications

| Agency | Classification |
|--------|----------------|
| ANATEL | Compliant      |



## Included Products

- |                      |   |  |
|----------------------|---|--|
| 760237971            | - | Fiber Indoor Cable, Low Smoke Zero Halogen Riser MPO Trunk Cable, 12 fiber, gel-free, singlemode G.657.A2/B2, feet jacket marking, yellow cable jacket color, Dca Flame Rating |
| N-012-MP-8G1-F12YL/D |   |  |
| 860637435            | - | LC/UPC Connector, Singlemode, Blue, Short Boot   |
| 860638318            | - | MPO12, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm  |