


UKXMPMXAL

Base Product

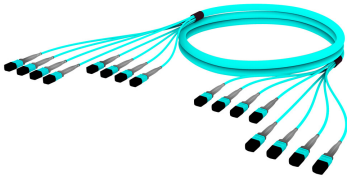

Ultra Low Loss (ULL) Multimode OM4 MPO12 (Unpinned) to MPO12 (Pinned), Armored Pre-terminated Trunk Cable, 96-Fiber, Low Smoke Zero Halogen (LSZH)

OBSOLETE

This product was discontinued on: April 30, 2024

Replaced By:

UKXMPMXCL

Ultra Low Loss (ULL) Multimode OM4 MPO12 (Unpinned) to MPO12 (Pinned), Armored Pre-terminated Trunk Cable, 96-Fiber, Low Smoke Zero Halogen (LSZH)

Product Classification

Regional Availability

Asia | Australia/New Zealand | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Fiber trunk cable assembly

Product Brand

SYSTIMAX ULL

Ordering Note

For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration | Not available in the United States or Canada

General Specifications

Connector A, quantity	8
Color, boot A	Black
Color, connector A	Aqua
Connector B, quantity	8
Color, boot B	Black
Color, connector B	Aqua
Construction Type	Armored Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-12/UPC Female
Interface Feature, connector A	Unpinned
Interface, Connector B	MPO-12/UPC Male


UKXMPMXAL

Interface Feature, connector B	Pinned
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	96

Dimensions

Breakout Length	33 in
Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

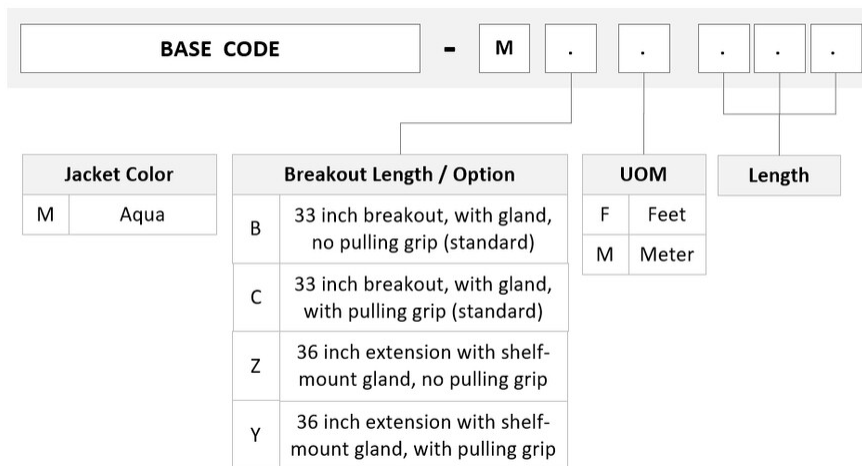

Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 ° 4.40 lb @ 90 °
--	---------------------------------

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM4, LazrSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Dual Rated LSZH/Riser Indoor

UKXMPMXAL

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



Included Products

760120097 N-096-MZ-5K-F12AQ	- Fiber indoor cable, LazrSPEED® Riser/LSZH rated, MPO Trunk, interlocking aluminum armored, Multimode OM4, 96 fiber multi-unit with 12 fiber subunits, Gel-free, Feet jacket marking, Aqua jacket color
860366210	- MPO12, ULTRA LOW LOSS, FEMALE, OM3/4, AQUA, 3mm
860366228	- MPO12, ULTRA LOW LOSS, MALE, OM3/4, AQUA, 3mm