


860662232

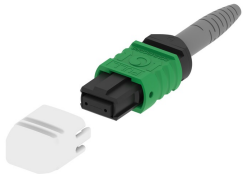

MPO8,ULL,Multimode,FEMALE,APC,GREEN,2 mm

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber connector

General Specifications

Color	Green
Color, boot	Black
Ferrule Geometry	Angled
Interface	MPO/APC Female
Interface Feature	Unpinned

Dimensions

Compatible Cable Diameter	2 mm 0.079 in
----------------------------------	-----------------

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM4 OM5
Insertion Loss Change, mating	0.3 dB
Optical Components Standard	ANSI/TIA-568-C.3
Insertion Loss Change, temperature	0.3 dB
Insertion Loss, maximum	0.2 dB
Return Loss, minimum	45 dB

Packaging and Weights

Packaging quantity	1
---------------------------	---

* Footnotes

Insertion Loss Change, mating TIA-568: Maximum insertion loss change after 500 matings

Insertion Loss Change, temperature Maximum insertion loss change from -10 °C to +60 °C (+14 °F to +140 °F)