


760253791

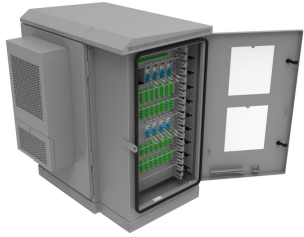

MSO All-In-One FLX-PON Cabinet, 288F, LC/APC, LGX Splitters, Dry Single Armored Loose Tube, 100 ft, 1x 288F Distribution Cables, 1x 24F Feeder Cable

Product Classification

| | |
|------------------------------|------------------------|
| Regional Availability | North America |
| Portfolio | CommScope® |
| Product Type | Fiber distribution hub |
| Product Brand | CommScope FLX™ |
| Product Series | FLX |
| Warranty | Two years |

General Specifications

| | |
|--|-----------------------------|
| Access | Front Rear Side |
| Accoustic Level, maximum | 60 dB |
| Alarm Type | Door alarm |
| Auxiliary Power Input | Yes |
| Cable Type | Armored - Single Loose Tube |
| Color | Light Gray (RAL 7035) |
| Distribution Cables, quantity | 1 |
| Distribution Ports, quantity | 288 |
| Fibers per Distribution Cable, quantity | 288 |
| Fibers per Feeder Cable, quantity | 24 |
| Interior LED light | Both chambers |
| Interface, Input | LC |
| Interface Feature, Input | APC |
| Mounting | Handhole Pad |
| Node Storage Capacity | 2 |
| Rack Storage | 13RU (19 in) |
| Split Ratio | Symmetrical |

760253791

| | |
|---------------------------------|----------------------|
| Splitter Slots, quantity | 12 |
| Splitter Type | 1 x 64 |
| Splitter, quantity | 4 |
| Heat Management | 1,500 W Thermosiphon |

Dimensions

| | |
|-----------------------|---------------------|
| Height | 1216 mm 47.874 in |
| Width | 1224 mm 48.189 in |
| Depth | 697 mm 27.441 in |
| Cable Length | 30.48 m 100 ft |
| Enclosure Size | Large |

Material Specifications

| | |
|----------------------|---------------|
| Finish | Powder coated |
| Material Type | Aluminum |

Environmental Specifications

| | |
|--------------------------------|-----------------------|
| Environmental Space | Above ground |
| Qualification Standards | Telcordia GR-487-CORE |

Packaging and Weights

| | |
|------------------------------|---------------------|
| Packaging quantity | 1 |
| Packaging Type | Pallet |
| Weight, net | 147.418 kg 325 lb |
| Weight, without cable | 122.924 kg 271 lb |

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|-----------------------------------|
| CHINA-ROHS | Above maximum concentration value |
| ROHS | Compliant/Exempted |
| UK-ROHS | Compliant/Exempted |



* Footnotes

760253791

Warranty

For more information, please consult our Product Warranty guidelines