


760254756 | C-024-LA-8W-M12BK/28G/GRP/E

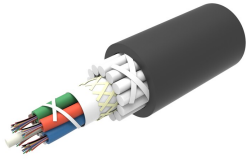

Indoor/Outdoor Low Smoke Zero Halogen, TeraSPEED® GRP Armoured, Stranded Loose Tube Fiber Optic Cable, 24-fiber, Singlemode OS2, Gel-filled, black. Provides Rodent Resistance.

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA
Portfolio	CommScope®
Product Type	Fiber indoor/outdoor cable
Product Series	C-LA


General Specifications

Armor Type	Non-metallic rods
Cable Type	Loose tube
Subunit Type	Gel-filled
Filler, quantity	2
Jacket Color	Black
Jacket Marking	Meters
Jacket Marking Method	Inkjet
Jacket Marking Text	COMMSCOPE GB OPTICAL CABLE 760254756 OS2 SM 24 FIBER EN50575 CLASS Dca [SERIAL NUMBER] [MM /YY] [METRE MARK]
Total Fiber Count	24

Dimensions

Cable Length	2000 m 6,561.68 ft
Buffer Tube/Subunit Diameter	2.8 mm 0.11 in
Diameter Over Jacket	15 mm 0.591 in

Representative Image

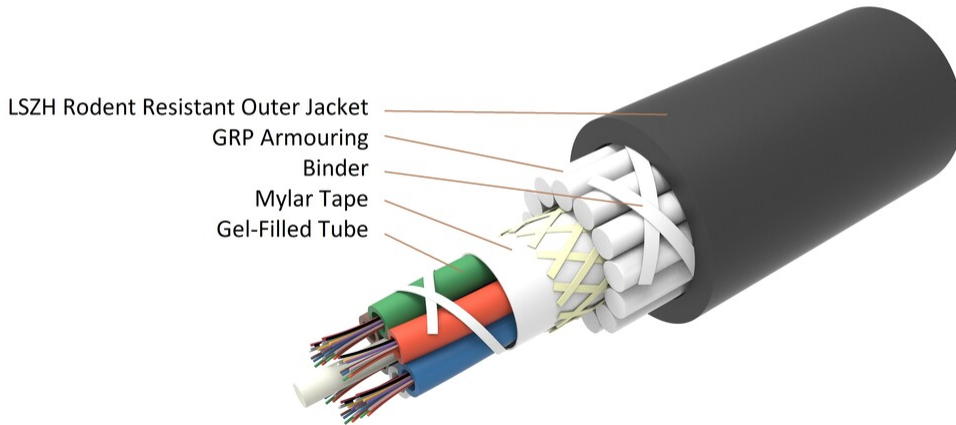

Mechanical Specifications

Minimum Bend Radius, loaded	465 mm 18.307 in
Minimum Bend Radius, unloaded	350 mm 13.78 in
Tensile Load, long term, maximum	6000 N 1,348.854 lbf
Tensile Load, short term, maximum	9000 N 2,023.281 lbf

Optical Specifications

Fiber Type	G.652.D and G.657.A1
-------------------	----------------------

Optical Specifications, Wavelength Specific

Attenuation, maximum	0.35 dB/km @ 1,300 nm 0.35 dB/km @ 1,550 nm 0.45 dB/km @ 1,310 nm
Standards Compliance	IEC 60794-1 TIA-492CAAB (OS2)

Environmental Specifications

Installation temperature	-5 °C to +50 °C (+23 °F to +122 °F)
Operating Temperature	-25 °C to +70 °C (-13 °F to +158 °F)
Storage Temperature	-20 °C to +70 °C (-4 °F to +158 °F)
EN50575 CPR Cable EuroClass Fire Performance	Eca
Environmental Space	Low Smoke Zero Halogen (LSZH)

Packaging and Weights

Cable weight

230 kg/km | 154.553 lb/kft

Included Products

CS-8W-250-EMEA - LightScope ZWP® Singlemode Fiber
250um

* Footnotes

Operating Temperature Specification applicable to non-terminated bulk fiber cable