

Building Fiber Termination Point


The BFTP wall-mountable Optic fiber outlet is a cable termination unit of optical blown cable for indoor use. The outlet is specially designed for an easy termination of a blown fiber cable and a micro duct facilitating a quick and reliable fiber optic connection.

This unit can accommodate with three adapters (LC duplex, 6 connections) and store up to 12 splices to connect an additional satellite unit in the building if required. It can be entered with a blown fiber tubing or with a small fiber cable, storage of a gas block device is possible. The clever design allows users to rotate the patch panel with the connectors facing the right side of the housing for easy access during installing.

The unit is made of self-extinguishing ABS UL V-0 and no metal parts are used. Closing is done by a reinforced plastic quarter turned lock covered with a security seal. The patch panel has a safety cover to prevent accidentally release of the connectors but can be removed if needed.


Features and benefits

- Compact design: 120 x 105 x 34 mm
- One feeder port at the bottom left, one satellite port at the top left
 - all with the wraparound facility,
 - one knock-out port in the back if cables arrive/leave at the wall side
- 6 drop connections possible
- Allows blown fiber tubing or small cables up to 10 mm
- Enables storage of a Gasblock device
- Houses up to 12 ANT splice protectors, to splice a cable for an additional satellite unit if required
- Adapter(s)/pigtail(s) on the applicable MIDs, adapters will have an inner shutter
- Locking done by a re-enforced plastic quarter turned plug, covered with a small security lid that hides the plug and preventing re-entry
- rotatable patch panel for easy installation, includes a safety cover above the triggers of the connectors to prevent accidentally removing by children.
- QR code on the carbon box and inside the product for a link to installation instructions
- IP50
- Material: LSZH, flame retardant and UV stable
- Includes:
 - 4x tie-wraps (2 x 80 mm)
 - Foam tape (200 x 15 mm)
 - 2x wall screws and 2x wall plugs (wall installation)
 - Plastic reinforced screw
 - Small lid (in a prepack) to secure locking screw
 - Two grommets (1 x 1 feeder cable, 10 mm max; 1 x drop cable, 7 mm max)

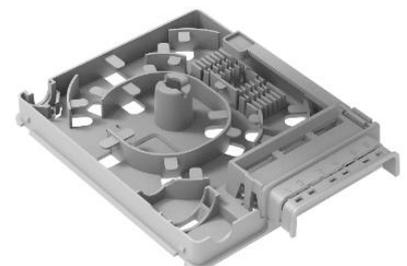


Product characteristics

Dimensions		
L x W x H	120 x 105 x 34 mm	
Cable ports		
feeder port	blown fiber tubing	5 - 10 mm
	cable	max 10 mm
satellite port	cable	max 6 mm
Capacity		
Splicing	up to 12 ANT splice protectors	
patching	up to 6 LC connections	
Color	RAL 7035	
Orientation	indoor	
sealing level	IP50	
flammability	UL 94 V-0	
Gasblock	not included	

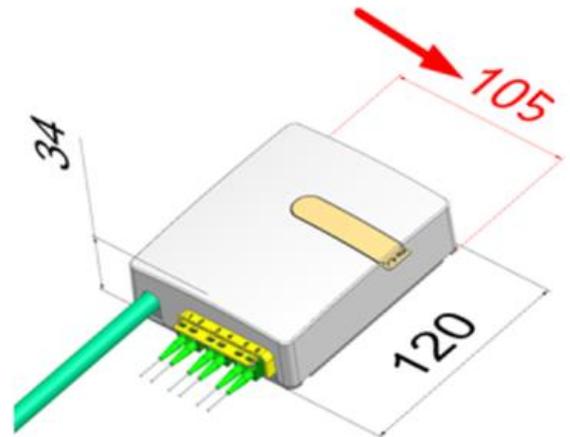

Product offering

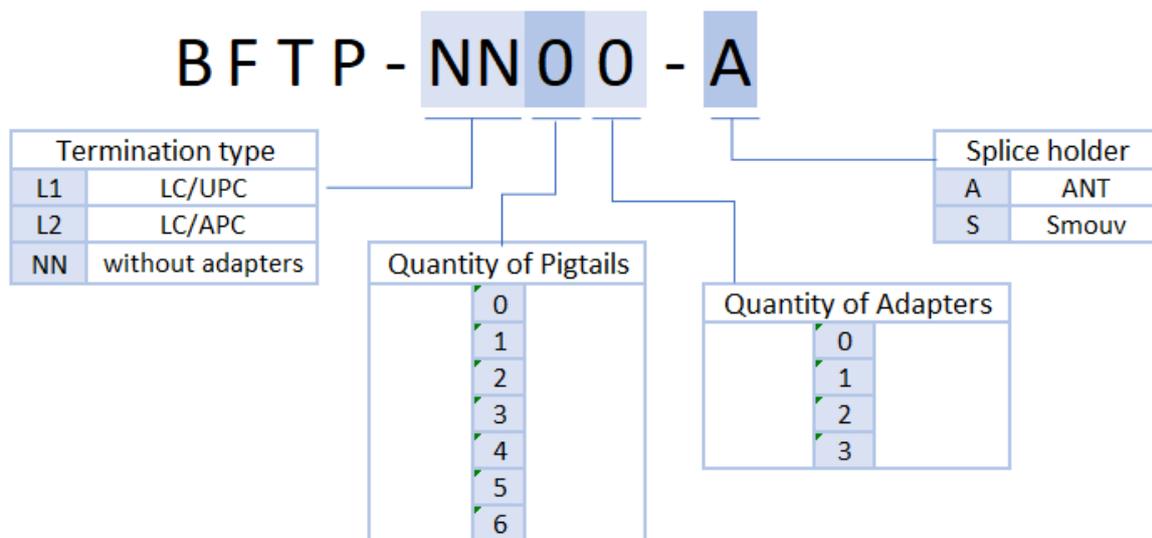

For technical assistance, customer service, or to report any missing/damaged parts, visit us at commscope.com/SupportCenter.

COMMSCOPE®

CommScope.com

Visit our website or contact your local CommScope representative for more information. © 2021 CommScope, Inc. All rights reserved.

Unless otherwise noted, all trademarks identified by ® or ™ are registered trademarks, respectively, of CommScope, Inc. This document is for planning purposes only and is not intended to modify or supplement any specifications or warranties relating to CommScope products or services. CommScope is committed to the highest standards of business integrity and environmental sustainability with a number of CommScope's facilities across the globe certified in accordance with international standards, including ISO 9001, TL 9000, and ISO 14001. Further information regarding CommScope's commitment can be found at www.commscope.com/About-Us/Corporate-Responsibility-and-Sustainability.

PA-116070-EN (12/22)