

UJXMXUCDH



Ultra Low Loss ULL LazrSPEED® 550 MPO(Pinned) to Unconnectorized Pre-terminated Trunk Cable, MPO12, 48-Fiber, LSZH Indoor/Outdoor, 12 fiber PmP

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Color, boot A	Black
Color, connector A	Black
Construction Type	Stranded
Fibers per Subunit, quantity	12
Furcation Color	Black
Interface, Connector A	MPO-12/UPC Male
Interface, Connector B	Unterminated
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Total Fibers, quantity	48

Dimensions

Breakout Length	33 in
Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

UJXXMXUCDH

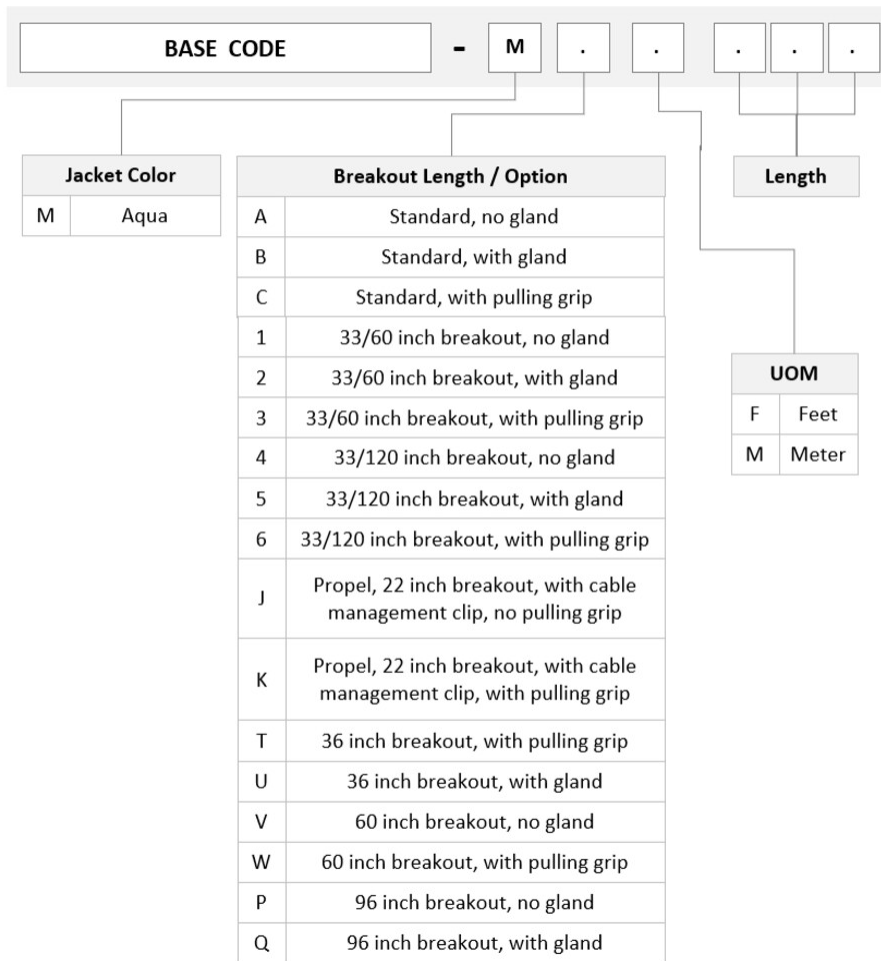

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM4, LazrSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
EN50575 CPR Cable EuroClass Fire Performance	Dca
Environmental Space	Dual Rated LSZH/Riser Indoor/Outdoor

Included Products

760160010 Z-048-MP-5K-F12BK/D	-	Fiber Indoor/Outdoor cable, LazrSPEED®, Low Smoke Zero Halogen Riser MPO Trunk Cable, 48
----------------------------------	---	--

UJXMXUCDH

fiber multi-unit with 12 fiber subunits, Gel-free, Multimode OM4, Feet jacket marking, Black jacket color, Dca flame rating