


760249511 | OCP-L5-02MGLEN-XX-(12COL/D)

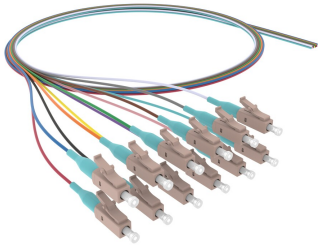

Fiber Optic Pigtail, Multi-fiber, Multimode, OM4, LC/PC to Stub, 0.9 mm diameter, 12 fibers, multicolor, 2 m

Product Classification

Regional Availability	EMEA
Product Type	Fiber pigtail, jacketed
Product Series	OCP

General Specifications

Connector A, quantity	12
Color, boot A	Aqua
Color, connector A	Beige
Interface, Connector A	LC/PC
Total Fibers, quantity	12

Dimensions

Cord Length	2 m 6.562 ft
Diameter Over Jacket	0.9 mm 0.035 in

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM4, LazrSPEED®

Environmental Specifications

Environmental Space	Low Smoke Zero Halogen (LSZH)
----------------------------	-------------------------------

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
--------	----------------

760249511 | OCP-L5-02MGLEN-XX-(12COL/D)

CHINA-ROHS

Below maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant/Exempted

