



COMMSCOPE®

Tower Reinforcement & Mod Parts  
Product Selection Guide

# QUICK REFERENCE

## MONOPOLE APPLICATION

<a href="#">MC-K6M-UK</a>	T-ARM UPGRADE - 6-FOOT	T-Arm Upgrade/Reinforcement Kit for 6' Face, Single sector only, 2-3/8" OD x 84", with Hardware for mounting to (9) 2-3/8" Antenna Pipes
<a href="#">MC-K6M-UK-3</a>	T-ARM UPGRADE - 6-FOOT	T-Arm Upgrade/Reinforcement Kit for 6' Face, 3- Sector, 2-3/8" OD x 84", with Hardware for mounting to (9) 2-3/8" Antenna Pipes
<a href="#">MC-K10M-UK</a>	T-ARM UPGRADE - 10-FOOT	T-Arm Upgrade/Reinforcement Kit for 10' Face, Single sector only, 2-3/8" OD x 126", with Hardware for mounting to (9) 2-3/8" Antenna Pipes
<a href="#">MC-K10M-UK-3</a>	T-ARM UPGRADE - 10-FOOT	T-Arm Upgrade/Reinforcement Kit for 10' Face, 3- Sector, 2-3/8" OD x 126", with Hardware for mounting to (9) 2-3/8" Antenna Pipes
<a href="#">MC-K12M-UK</a>	T-ARM UPGRADE - 12-FOOT	T-Arm Upgrade/Reinforcement Kit for 12' Face, Single sector only, 2-3/8" OD x 150", with Hardware for mounting to (12) 2-3/8" Antenna Pipes
<a href="#">MC-K12M-UK-3</a>	T-ARM UPGRADE - 12-FOOT	T-Arm Upgrade/Reinforcement Kit for 12' Face, 3- Sector, 2-3/8" OD x 150", with Hardware for mounting to (12) 2-3/8" Antenna Pipes
<a href="#">MC-K14M-UK</a>	T-ARM UPGRADE - 14-FOOT	T-Arm Upgrade/Reinforcement Kit for 14' Face, Single sector only, 2-3/8" OD x 174", with Hardware for mounting to (12) 2-3/8" Antenna Pipes
<a href="#">MC-K14M-UK-3</a>	T-ARM UPGRADE - 14-FOOT	T-Arm Upgrade/Reinforcement Kit for 14' Face, 3- Sector, 2-3/8" OD x 174", with Hardware for mounting to (12) 2-3/8" Antenna Pipes
<a href="#">MUK-MSK8</a>	CORNER SUPPORT BRACKET KIT	Universal Corner Bracket Support Kit, One Corner; Mounts to Pipe up to 4-1/2", Pipe - No Angle Braces Included.
<a href="#">MUK-MSK10</a>	WIRE ROPE ROUTING BRACKET	Wire Rope Routing Bracket Accessory for Collar/Ring Mount, Attaches to MUK-PLK7 or MUK-PLK7Q collar - not included
<a href="#">MUK-PLK1</a>	SUPPORT RAIL KIT	Top Support Rail kit for monopole platforms, 2-7/8" x 150", with adjustable corner braces and Hardware for mounting (12) 2-7/8" Antenna Pipes
<a href="#">MUK-PLK1Q</a>	4-SIDED SUPPORT RAIL KIT	4-sector Support Rail Kit with 2-7/8" x 150" Rail, Adjustable Corner Reinforcement, & Crossover Kits for 2-3/8" or 2-7/8" Pipes
<a href="#">MUK-PLK2</a>	PLATFORM SUPPORT RAIL BRACE KIT	Top Support Rail Corner Brace Kit for monopole platforms - attaches to 2-7/8" Horizontal
<a href="#">MUK-PLK3</a>	SUPPORT RAIL CORNER BRACKET	Top Support Rail Corner Brace Brackets for monopole platforms. One Corner with 2-7/8" Pipe connections. No Angle Braces Included.
<a href="#">MUK-PLK4</a>	4-SIDED SUPPORT RAIL CORNER BRACKET	4-Sector Support Rail Corner Bracing Brackets for monopole platforms. One Corner with 2-7/8" Pipe connections. No Angle Braces Included.
<a href="#">MUK-PLK5</a>	KICKER KIT	Kicker Support Arms, 3" x 3" x 96" Angle with Connecting Brackets and Hardware for 3" to 6" square or 3-1/2" to 4-1/2" OD Stand-offs, 3 sectors. Attaches to MUK-PLK7 collar - not included.
<a href="#">MUK-PLK5Q</a>	4-SIDED KICKER KIT	4-sector Kicker Support Arms, 3" x 3" x 96" Angle with Connecting Brackets and Hardware for 3" to 6" square or 3-1/2" to 4-1/2" OD Stand-offs, 4 sectors. Attaches to MUK-PLK7Q collar - not included.
<a href="#">MUK-PLK6</a>	DUAL KICKER KIT	Dual Pivoting Kicker Support Arms, 2-1/2" x 2-1/2" x 60" Angle with Connecting Brackets for up to 4.5" OD Horizontals, Single Sector. Attaches to MUK-PLK7 collar - not included
<a href="#">MUK-PLK7</a>	MONOPOLE COLLAR MOUNT ASSEMBLY	Collar / Ring Mount for 12" to 45" OD Monopoles with 6" x 6" x 5/8" bolt pattern
<a href="#">MUK-PLK7Q</a>	4-SIDED COLLAR MOUNT ASSEMBLY	4-sector Collar / Ring Mount for 14" to 60" monopoles with 6" x 6" x 5/8" bolt pattern
<a href="#">MUK-PLK7S</a>	SMALL POLE ADAPTER	Small Pole Adapter for Collar/Ring Mount (single sector); 3-sector down to 6" Pole OD; 4-Sector down to 8.5" Pole OD
<a href="#">MUK-PLK8</a>	SUPPORT RAIL BRACING KIT - ANGLE	Monopole Platform Vertical Top Rail Reinforcement Kit (Angle), One Sector Only. Attaches up to 3-1/2" OD horizontal & up to 6" square standoff
<a href="#">MUK-PLK9</a>	COLLAR MOUNT STANDOFF ADAPTER	Collar/Ring Mount Standoff Adapter; Attaches to MUK-PLK7 or MUK-PLK7Q collar- not included
<a href="#">MUK-PLK10</a>	SUPPORT RAIL BRACING KIT - PIPE	Monopole Platform Vertical Top Rail Reinforcement Kit (Pipe), One Sector Only. Attaches up to 4-1/2" OD horizontal & up to 6" square standoff
<a href="#">MUK-SFK4</a>	SUPPORT RAIL BRACING KIT, T-ARM	Reinforcement Arm for T-Arm Kit, 3" x 3" x 72" Square Tube with hardware for 3-1/2" OD Horizontal, 1 sector. Attaches to MUK-PLK7 collar - not included.

## MONOPOLE APPLICATION

<a href="#">PVS-050B-U</a>	TOP RAIL REINFORCEMENT KIT	Top Rail Reinforcement Kit for Monopole Platforms
<a href="#">RK-36-3M</a>	MONOPOLE KICKER KIT - 36"	3-Sector with 36" HD Pipe Kicker - Includes 12" – 50" OD Collar/Ring Mount
<a href="#">RK-60-3M</a>	MONOPOLE KICKER KIT - 60"	3-Sector with 60" HD Pipe Kicker - Includes 12" – 50" OD Collar/Ring Mount
<a href="#">RK-36-4L</a>	4-SIDED MONOPOLE KICKER KIT - 36" LARGE OD	4-Sector with 36" HD Pipe Kicker Includes - 30" – 60" OD Collar/Ring Mount
<a href="#">RK-60-4L</a>	4-SIDED MONOPOLE KICKER KIT - 60" LARGE OD	4-Sector with 60" HD Pipe Kicker - Includes 30" – 60" OD Collar/Ring Mount
<a href="#">RK-36-4S</a>	4-SIDED MONOPOLE KICKER KIT - 36"	4-Sector with 36" HD Pipe Kicker - Includes 10" – 30" OD Collar/Ring Mount
<a href="#">RK-60-4S</a>	4-SIDED MONOPOLE KICKER KIT- 60"	4-Sector with 60" HD Pipe Kicker - Includes 10" – 30" OD Collar/Ring Mount
<a href="#">VSRC-MM-1550</a>	VSRC SERIES MONOPOLE REINFORCEMENT KIT	Interlocking Channel Supports Adjustable from 34.5" to 57.5" Plus Vertical & Horizontal Adjustments - Includes 15" – 50" OD Collar/Ring Mount
<a href="#">VSRA-MM-B3</a>	MONOPOLE V-STABILIZER - ADJUSTABLE	3-Sector with Adjustable Angle Supports - Includes 12" – 50" OD Collar/Ring Mount
<a href="#">VSR-MS-B</a>	MONOPOLE V-STABILIZER	3-Sector with 60" Channel Supports - Includes 10" – 30" OD Collar/Ring Mount

# QUICK REFERENCE

TOWER APPLICATION		
<a href="#">MUK-SFK1</a>	STIFF ARM KIT	Tieback Bracket / Stiff Arm, 2-3/8" OD x 12 ft Pipe with Attachment Hardware, for 1-1/2" to 8" OD or 60 degree angle tower leg
<a href="#">MUK-SFK3</a>	V-BRACING FOR SECTOR MOUNT	V-Stabilizer for Tower with saddle clamps for 1.5" - 8" Tower legs, Dual Pivoting Angle Arms, 96" long, attaches up to 4-1/2" OD horizontals
<a href="#">MUK-SFK3-SL</a>	V-BRACING FOR SMALL TOWER LEG	V-Stabilizer for Small Tower Leg with Saddle Clamps for up to 3-1/2" Tower legs, Dual Pivoting Angle Arms, 96" long, attaches up to 4-1/2" OD horizontals
<a href="#">VSR-TL-B</a>	V-STABILIZER KIT - LARGE LEG	48" Channel Supports - 8" – 16" OD Tower Legs
<a href="#">VSR-TS-B</a>	V-STABILIZER KIT	48" Channel Supports - 2" – 8" OD Tower Legs
<a href="#">VSR-TS-B</a>	ADJUSTABLE V-STABILIZER KIT	60" Adjustable Angle Supports - 2" – 8" OD Tower Legs
<a href="#">VSRAL-TS-B</a>	ADJUSTABLE V-STABILIZER KIT - LARGE LEG	60" Adjustable Angle Supports - 8" – 16" OD Tower Legs
<a href="#">VSR-TL-B</a>	VSRC SERIES TOWER REINFORCEMENT KIT - LARGE LEG	Interlocking Channel Supports Adjustable from 34.5" to 57.5" Plus Vertical & Horizontal Adjustments - 8" – 16" OD Tower Legs
<a href="#">VSR-TS-B</a>	VSRC SERIES TOWER REINFORCEMENT KIT	Interlocking Channel Supports Adjustable from 34.5" to 57.5" Plus Vertical & Horizontal Adjustments - 2" – 8" OD Tower Legs
<a href="#">VSRDUAL-TS-B</a>	DUAL V-STABILIZER KIT	60" Pipe Supports - 2" – 8" OD Tower Legs
<a href="#">VSRDUAL-TS-B-HD</a>	HEAVY DUTY DUAL V-STABILIZER KIT	60" HD Pipe Supports - 2" – 8" OD Tower Legs
<a href="#">VSRDUALA-TS-B</a>	DUAL ADJUSTABLE V-STABILIZER KIT	60" Adjustable Angle Supports - 2" – 8" OD Tower Legs
<a href="#">VSRDUALAL-TS-B</a>	DUAL ADJUSTABLE V-STABILIZER KIT - LARGE LEG	60" Adjustable Angle Supports - 8" – 16" OD Tower Legs

## HARDWARE KITS

<a href="#">MUK-AL333</a>	CLIP ANGLE	Set of 2 Clip Angles with 5/8" x 2" Hardware
<a href="#">MUK-MSK1</a>	SMALL CROSSOVER PLATE	Small Crossover Plate, connects 2-3/8" and 2-7/8" OD Pipes
<a href="#">MUK-MSK2</a>	MEDIUM CROSSOVER PLATE	Medium Crossover Plate, connects 2-3/8" - 2-7/8" pipes to 3-1/2" - 4" pipes
<a href="#">MUK-MSK3</a>	PIPE TO PIPE CLAMP, 1-1/2" to 4-1/2"	Pipe to Pipe Clamps for 1-1/2" to 4-1/2" Pipes
<a href="#">MUK-MSK3D</a>	CLAMP, PIPE TO PIPE, 1-1/2" TO 3-1/2", HD	HD Pipe to Pipe Clamps, Wide, for 1-1/2" to 3-1/2" Pipes, with double threaded Rod
<a href="#">MUK-MSK4</a>	PIPE LEVELING KIT	Tapered Pipe Mount Leveling Kit, attaches up to 8" OD or 60 degree angle Tower Legs, For Pipes 2-3/8" to 4-1/2" OD, U-Bolts sold separately
<a href="#">MUK-MSK5</a>	LARGE CROSSOVER PLATE	Large Crossover Plate, connects 2-3/8" - 2-7/8" pipes to 4" - 4-1/2" pipes
<a href="#">MUK-MSK6</a>	DUAL CROSSOVER PLATE	Dual Cross Over Plate, Mounts (2) 3-1/2" to 4-1/2" Pipes to 4" or 6" Square Tube
<a href="#">MUK-MSK7</a>	CROSSOVER PLATE, PIPE TO ANGLE	Pipe to Angle Cross Over Plate, Mounts up to 4-1/2" Pipe to Angled member
<a href="#">MUK-MSK9</a>	LEG CLAMP, 1/2" TO 3-1/2"	Small Tower Leg Clamp, Mounts to 1/2" to 3-1/2" Round or Up to 3" Angle Tower legs
<a href="#">MUK-MSK12</a>	UNIVERSAL CROSSOVER PLATE	Universal Crossover Plate, connects up to 4-1/2" OD x 4-1/2" OD Pipe
<a href="#">MUK-MSK13</a>	UNIVERSAL CHANNEL CROSSOVER	Universal Channel Crossover Plate, connects up to 4-1/2" OD x 3-1/2" OD Pipe
<a href="#">MUK-MSK14</a>	UNIVERSAL ADJUSTABLE CROSSOVER	Universal Adjustable Crossover Plate, connects up to 2-3/8" OD x 3-1/2" OD Pipe
<a href="#">RMPP-2001</a>	RING MOUNT PRESSURE PLATE	Ring Mount Pressure Plate Bracket - One Sector
<a href="#">SCG-002</a>	CABLE GUIDE - ROUND	Clamping guide to protect wire cable - Mounts to round members 1.5"-4"
<a href="#">SCG-003</a>	CABLE GUIDE - ROUND & ANGLE	Clamping guide to protect wire cable - Mounts to round members 1.5-8"; 90° Angle up to 6"; 60° Angle up to 8"
<a href="#">SCG-004</a>	CABLE GUIDE - SQUARE	Clamping guide to protect wire cable - Mounts to Square members up to 6"
<a href="#">SCG-005</a>	CABLE GUIDE - COLLARS	Clamping guide to protect wire cable - Mounts to monopole collars

# MONOPOLE APPLICATION

## MC-K6M-UK

### T-ARM UPGRADE - 6-FOOT

T-Arm Upgrade/Reinforcement Kit for 6' Face, Single Sector only, 2-3/8" OD x 84", with Hardware for mounting to (9) 2-3/8" Antenna Pipes



## MC-K10M-UK

### T-ARM UPGRADE - 10-FOOT

T-Arm Upgrade/Reinforcement Kit for 10' Face, Single Sector only, 2-3/8" OD x 126", with Hardware for mounting to (9) 2-3/8" Antenna Pipes



## MC-K6M-UK-3

### T-ARM UPGRADE - 6-FOOT

T-Arm Upgrade/Reinforcement Kit for 6' Face, 3- Sector, 2-3/8" OD x 84", with Hardware for mounting to (9) 2-3/8" Antenna Pipes



## MC-K10M-UK-3

### T-ARM UPGRADE - 10-FOOT

T-Arm Upgrade/Reinforcement Kit for 10' Face, 3- Sector, 2-3/8" OD x 126", with Hardware for mounting to (9) 2-3/8" Antenna Pipes





## MC-K12M-UK

### T-ARM UPGRADE - 12-FOOT

T-Arm Upgrade/Reinforcement Kit for 12' Face, Single Sector only, 2-3/8" OD x 150", with Hardware for mounting to (12) 2-3/8" Antenna Pipes



## MC-K14M-UK

### T-ARM UPGRADE - 14-FOOT

T-Arm Upgrade/Reinforcement Kit for 14' Face, Single Sector only, 2-3/8" OD x 174", with Hardware for mounting to (12) 2-3/8" Antenna Pipes



## MC-K12M-UK-3

### T-ARM UPGRADE - 12-FOOT

T-Arm Upgrade/Reinforcement Kit for 12' Face, 3- Sector, 2-3/8" OD x 150", with Hardware for mounting to (12) 2-3/8" Antenna Pipes



## MC-K14M-UK-3

### T-ARM UPGRADE - 14-FOOT

T-Arm Upgrade/Reinforcement Kit for 14' Face, 3- Sector, 2-3/8" OD x 174", with Hardware for mounting to (12) 2-3/8" Antenna Pipes



# MONOPOLE APPLICATION



## MUK-MSK8

### CORNER SUPPORT BRACKET KIT

Universal Corner Bracket Support Kit, One Corner; Mounts to Pipe up to 4-1/2", Pipe - No Angle Braces Included.

## MUK-PLK1

### SUPPORT RAIL KIT

Top Support Rail kit for monopole platforms, 2-7/8" x 150", with adjustable corner braces and Hardware for mounting (12) 2-7/8" Antenna Pipes



## MUK-MSK10

### WIRE ROPE ROUTING BRACKET

Wire Rope Routing Bracket Accessory for Collar/Ring Mount, Attaches to MUK-PLK7 or MUK-PLK7Q collar - not included

## MUK-PLK1Q

### 4-SIDED SUPPORT RAIL KIT

4-sector Support Rail Kit with 2-7/8" x 150" Rail, Adjustable Corner Reinforcement, & Crossover Kits for 2-3/8" or 2-7/8" Pipes







## MUK-PLK2

### PLATFORM SUPPORT RAIL BRACE KIT

Top Support Rail Corner Brace Kit for monopole platforms - attaches to 2-7/8" Horizontal

## MUK-PLK4

### 4-SIDED SUPPORT RAIL CORNER BRACKET

4-Sector Support Rail Corner Bracing Brackets for monopole platforms. One Corner with 2-7/8" Pipe connections. No Angle Braces Included.



## MUK-PLK3

### SUPPORT RAIL CORNER BRACKET

Top Support Rail Corner Brace Brackets for monopole platforms. One Corner with 2-7/8" Pipe connections. No Angle Braces Included.

## MUK-PLK5

### KICKER KIT

Kicker Support Arms, 3" x 3" x 96" Angle with Connecting Brackets and Hardware for 3" to 6" square or 3-1/2" to 4-1/2" OD Stand-offs, 3 sectors. Attaches to MUK-PLK7 collar - not included.



# MONOPOLE APPLICATION



## MUK-PLK5Q

### 4-SIDED KICKER KIT

4-sector Kicker Support Arms, 3" x 3" x 96" Angle with Connecting Brackets and Hardware for 3" to 6" square or 3-1/2" to 4-1/2" OD Stand-offs, 4 sectors. Attaches to MUK-PLK7Q collar - not included.

## MUK-PLK7

### MONOPOLE COLLAR MOUNT ASSEMBLY

Collar / Ring Mount for 12" to 45" OD Monopoles with 6" x 6" x 5/8" bolt pattern



## MUK-PLK6


### DUAL KICKER KIT


Dual Pivoting Kicker Support Arms, 2-1/2" x 2-1/2" x 60" Angle with Connecting Brackets for up to 4.5" OD Horizontals, Single Sector. Attaches to MUK-PLK7 collar - not included.

## MUK-PLK7Q

### 4-SIDED COLLAR MOUNT ASSEMBLY

4-sector Collar / Ring Mount for 14" to 60" monopoles with 6" x 6" x 5/8" bolt pattern

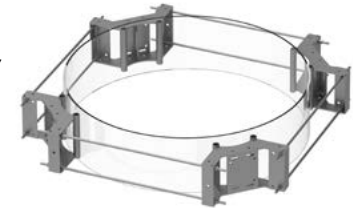

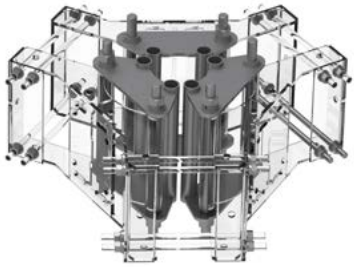

## MUK-PLK7S


### SMALL POLE ADAPTER

Small Pole Adapter for Collar/Ring Mount (single sector); 3-sector down to 6" Pole OD; 4-Sector down to 8.5" Pole OD

## MUK-PLK9

### COLLAR MOUNT STANDOFF ADAPTER

Collar/Ring Mount Standoff Adapter; Attaches to MUK-PLK7 or MUK-PLK7Q collar- not included

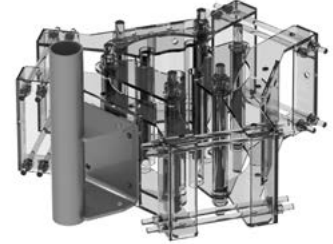

## MUK-PLK8

### SUPPORT RAIL BRACING KIT - ANGLE

Monopole Platform Vertical Top Rail Reinforcement Kit (Angle), One Sector Only. Attaches up to 3-1/2" OD horizontal & up to 6" square standoff

## MUK-PLK10

### SUPPORT RAIL BRACING KIT - PIPE

Monopole Platform Vertical Top Rail Reinforcement Kit (Pipe), One Sector Only. Attaches up to 4-1/2" OD horizontal & up to 6" square standoff



# MONOPOLE APPLICATION



## MUK-SFK4

### SUPPORT RAIL BRACING KIT, T-ARM

"Reinforcement Arm for T-Arm Kit, 3" x 3" x 72" Square Tube with hardware for 3-1/2" OD Horizontal, 1 sector. Attaches to MUK-PLK7 collar - not included."



## PVS-050B-U

### TOP RAIL REINFORCEMENT KIT

Top Rail Reinforcement Kit for Monopole Platforms

## RK-36-3M

### MONOPOLE KICKER KIT - 36"

3-Sector with 36" HD Pipe Kicker - Includes 12" - 50" OD Collar/Ring Mount



## RK-60-3M

### MONOPOLE KICKER KIT - 60"

3-Sector with 60" HD Pipe Kicker - Includes 12" - 50" OD Collar/Ring Mount



# MONOPOLE APPLICATION



## RK-36-4L

### 4-SIDED MONOPOLE KICKER KIT - 36" LARGE OD

4-Sector with 36" HD Pipe Kicker Includes - 30" – 60" OD Collar/Ring Mount

## RK-36-4S

### 4-SIDED MONOPOLE KICKER KIT - 36"

4-Sector with 36" HD Pipe Kicker - Includes 10" – 30" OD Collar/Ring Mount



## RK-60-4L

### 4-SIDED MONOPOLE KICKER KIT - 60" LARGE OD

4-Sector with 60" HD Pipe Kicker - Includes 30" – 60" OD Collar/Ring Mount

## RK-60-4S

### 4-SIDED MONOPOLE KICKER KIT- 60"

4-Sector with 60" HD Pipe Kicker - Includes 10" – 30" OD Collar/Ring Mount





# MONOPOLE APPLICATION



## VSRC-MM-1550

### VSRC SERIES MONOPOLE REINFORCEMENT KIT

Interlocking Channel Supports Adjustable from 34.5" to 57.5" Plus Vertical & Horizontal Adjustments - Includes 15" – 50" OD Collar/Ring Mount

## VSR-MS-B

### MONOPOLE V-STABILIZER

3-Sector with 60" Channel Supports - Includes 10" – 30" OD Collar/Ring Mount



## VSRA-MM-B3

### MONOPOLE V-STABILIZER - ADJUSTABLE

3-Sector with Adjustable Angle Supports - Includes 12" – 50" OD Collar/Ring Mount







## MUK-SFK1

### STIFF ARM KIT

Tieback Bracket / Stiff Arm, 2-3/8" OD x 12 ft Pipe with Attachment Hardware, for 1-1/2" to 8" OD or 60 degree angle tower leg



## MUK-SFK3

### V-BRACING FOR SECTOR MOUNT

V-Stabilizer for Tower with saddle clamps for 1.5"- 8" Tower legs, Dual Pivoting Angle Arms, 96" long, attaches up to 4-1/2" OD horizontals

## MUK-SFK3-SL

### V-BRACING FOR SMALL TOWER LEG

V-Stabilizer for Small Tower Leg with Saddle Clamps for up to 3-1/2" Tower legs, Dual Pivoting Angle Arms, 96" long, attaches up to 4-1/2" OD horizontals



# TOWER APPLICATION



## VSR-TL-B

### V-STABILIZER KIT - LARGE LEG

48" Channel Supports - 8" – 16"  
OD Tower Legs



## VSR-TS-B

### V-STABILIZER KIT

48" Channel Supports - 2" – 8" OD  
Tower Legs

## VSRA-TS-B

### ADJUSTABLE V-STABILIZER KIT

60" Adjustable Angle Supports -  
2" – 8" OD Tower Legs



## VSRAL-TS-B

### ADJUSTABLE V-STABILIZER KIT - LARGE LEG

60" Adjustable Angle Supports -  
8" – 16" OD Tower Legs





## VSRC-TL-B

### VSRC SERIES TOWER REINFORCEMENT KIT - LARGE LEG

Interlocking Channel Supports  
Adjustable from 34.5" to 57.5" Plus  
Vertical & Horizontal Adjustments -  
8" - 16" OD Tower Legs

## VSRDUAL-TS-B

### DUAL V-STABILIZER KIT

60" Pipe Supports - 2" - 8" OD  
Tower Legs



## VSRC-TS-B

### VSRC SERIES TOWER REINFORCEMENT KIT

Interlocking Channel Supports  
Adjustable from 34.5" to 57.5" Plus  
Vertical & Horizontal Adjustments -  
2" - 8" OD Tower Legs


## VSRDUAL-TS-B-HD

### HEAVY DUTY DUAL V-STABILIZER KIT

60" HD Pipe Supports - 2" - 8" OD  
Tower Legs




# TOWER APPLICATION

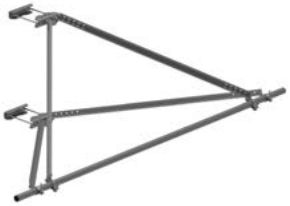

## VSRDUALA-TS-B

### DUAL ADJUSTABLE V-STABILIZER KIT

60" Adjustable Angle Supports -  
2" – 8" OD Tower Legs

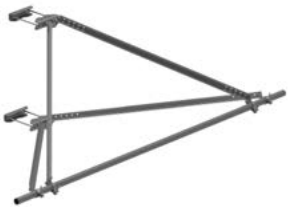

## VSRDUALAL-TS-B

### DUAL ADJUSTABLE V-STABILIZER KIT - LARGE LEG

60" Adjustable Angle Supports -  
8" – 16" OD Tower Legs





## MUK-AL333 CLIP ANGLE

Set of 2 Clip Angles with 5/8" x 2"  
Hardware

## MUK-MSK2 MEDIUM CROSSOVER PLATE

Medium Crossover Plate, connects  
2-3/8" - 2-7/8" pipes to 3-1/2" - 4" pipes



## MUK-MSK1 SMALL CROSSOVER PLATE

Small Crossover Plate, connects 2-3/8"  
and 2-7/8" OD Pipes

## MUK-MSK3 PIPE TO PIPE CLAMP, 1-1/2" TO 4-1/2"

Pipe to Pipe Clamps for 1-1/2" to 4-1/2"  
Pipes





# HARDWARE KITS



## MUK-MSK3D CLAMP, PIPE TO PIPE, 1-1/2" TO 3-1/2", HD

HD Pipe to Pipe Clamps, Wide, for 1-1/2" to 3-1/2" Pipes, with double threaded Rod

## MUK-MSK5 LARGE CROSSOVER PLATE

Large Crossover Plate, connects 2-3/8"-2-7/8" pipes to 4" - 4-1/2" pipes



## MUK-MSK4 PIPE LEVELING KIT

Tapered Pipe Mount Leveling Kit, attaches up to 8" OD or 60 degree angle Tower Legs, For Pipes 2-3/8" to 4-1/2" OD, U-Bolts sold separately

## MUK-MSK6 DUAL CROSSOVER PLATE

Dual Cross Over Plate, Mounts (2) 3-1/2" to 4-1/2" Pipes to 4" or 6" Square Tube







## **MUK-MSK7** **CROSSOVER PLATE, PIPE TO ANGLE**

Pipe to Angle Cross Over Plate, Mounts up to 4-1/2" Pipe to Angled member

## **MUK-MSK12** **UNIVERSAL CROSSOVER PLATE**

Universal Crossover Plate, connects up to 4-1/2" OD x 4-1/2" OD Pipe




## **MUK-MSK9** **LEG CLAMP, 1/2" TO 3-1/2"**

Small Tower Leg Clamp, Mounts to 1/2" to 3-1/2" Round or Up to 3" Angle Tower legs

## **MUK-MSK13** **UNIVERSAL CHANNEL CROSSOVER**

Universal Channel Crossover Plate, connects up to 4-1/2" OD x 3-1/2" OD Pipe

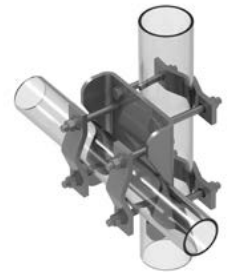

# HARDWARE KITS



## MUK-MSK14 UNIVERSAL ADJUSTABLE CROSSOVER

Universal Adjustable Crossover Plate, connects up to 2-3/8" OD x 3-1/2" OD Pipe

## SCG-002 CABLE GUIDE - ROUND

Clamping guide to protect wire cable - Mounts to round members 1.5"-4"



## RMPP-2001 RING MOUNT PRESSURE PLATE

Ring Mount Pressure Plate Bracket - One Sector

## SCG-003 CABLE GUIDE - ROUND & ANGLE

Clamping guide to protect wire cable - Mounts to round members 1.5-8"; 90° Angle up to 6"; 60° Angle up to 8"





## SCG-004 CABLE GUIDE - SQUARE


Clamping guide to protect wire cable -  
Mounts to Square members up to 6"



## SCG-005 CABLE GUIDE - COLLARS

Clamping guide to protect wire cable -  
Mounts to monopole collars



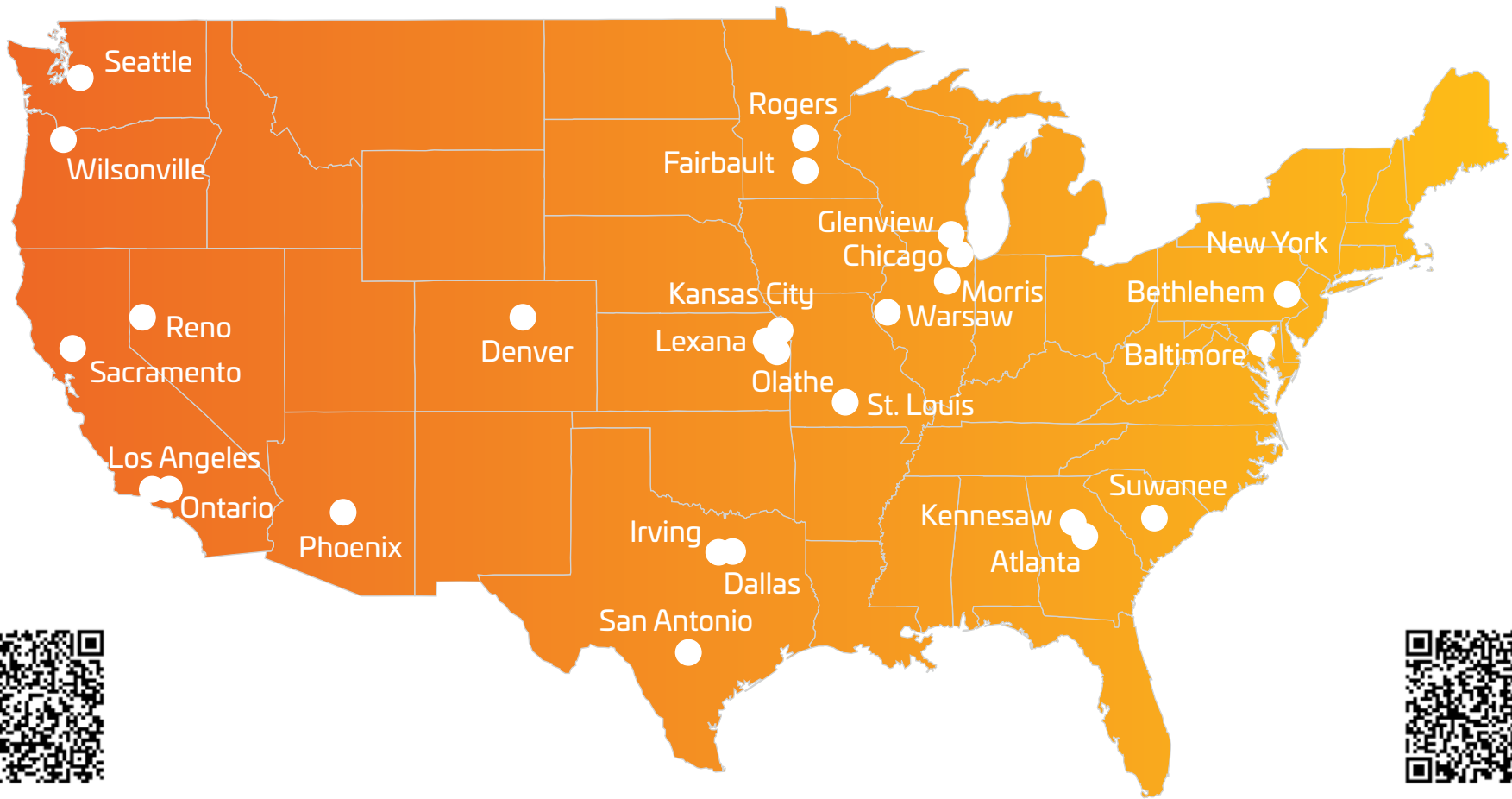

Latest online guide



View our full product line

## Available From

TALLEY®

T tessco

PRIMUS

KGPCo.

ANIXER

GraybaR.

For product support questions,  
email us directly at: [Steelproducts@commscope.com](mailto:Steelproducts@commscope.com)

For Engineering Resources and More:  
Register or Log Into ["My CommScope"](#)

CommScope pushes the boundaries of communications technology with game-changing ideas and ground-breaking discoveries that spark profound human achievement.

We collaborate with our customers and partners to design, create and build the world's most advanced networks. It is our passion and commitment to identify the next opportunity and realize a better tomorrow. Discover more at [commscope.com](https://commscope.com).

[commscope.com](https://commscope.com)

Visit our website or contact your local CommScope representative for more information.

© 2023 CommScope, Inc. All rights reserved. CommScope and the CommScope logo are registered trademarks of CommScope and/or its affiliates in the U.S. and other countries. For additional trademark information see <https://www.commscope.com/trademarks>. All product names, trademarks and registered trademarks are property of their respective owners.