


# WSC-SH034810

---

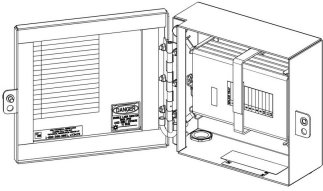

WSC Wall Splice Cabinet for MDU applications, indoor/outdoor, for up to 48 fibers, includes 4 splice trays with mechanical ribbon, no key lock

## Product Classification

<b>Regional Availability</b>	North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber wall box

## General Specifications

<b>Functionality</b>	Splicing
<b>Access</b>	Front
<b>Cable Color</b>	White
<b>Cable Type</b>	Pigtails - Stranded
<b>Door, quantity</b>	1
<b>Enclosure Color</b>	Putty white
<b>Front Door Type</b>	Single hinged
<b>Interface</b>	Splicing only
<b>Lock Type</b>	Locking bolt
<b>Mounting</b>	Wall
<b>Splice Trays</b>	Included
<b>Splicing Type</b>	Mechanical, mass fusion

## Dimensions

<b>Height</b>	273 mm   10.748 in
<b>Width</b>	255 mm   10.039 in
<b>Depth</b>	89 mm   3.504 in

## Environmental Specifications

<b>Environmental Space</b>	Outdoor
<b>Qualification Standards</b>	NEMA, Type 4

# WSC-SH034810

---

## Packaging and Weights

<b>Packaging quantity</b>	1
<b>Packaging Type</b>	Box   Carton

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

