


ULXQZLUT8

Base Product

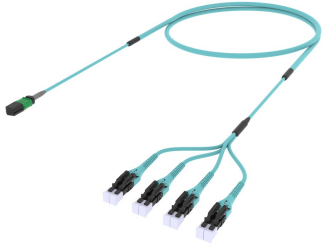

Ultra Low Loss ULL OM4 MPO8 APC pinned to LC/UPC Uniboot Ruggedized fanout Cable, 8-Fiber, Plenum, 8 fiber PmP 2.0 mm

Product Classification

Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Ruggedized fanout

Product Brand

Propel | SYSTIMAX ULL

Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	1
Color, boot A	Gray
Color, connector A	Aqua
Connector B, quantity	8
Color, boot B	Aqua
Color, connector B	Black
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-08/APC Male
Interface, Connector B	LC/UPC
Interface Feature, connector B	Uniboot
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	8

ULXQZLUT8

UK-ROHS

Compliant/Exempted



Included Products

- | | | |
|------------------------------------|---|--|
| 760248178
P-008-MP-5K-F08AQ/20T | - | Fiber indoor cable, LazrSPEED® Plenum for MPO Trunks, 8 fiber, Multimode OM4, Feet jacket marking, Aqua jacket color |
| 860658161 | - | 2.0 mm LC/UPC Uniboot GEN 1.5, Aqua |
| 860662230 | - | MPO8,ULL,Multimode,MALE,APC,GREEN,2 mm |