


MC-S10M-12-96

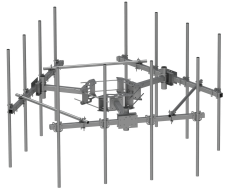

Monopole Co-location Square Tube T-Frame kit for 15 in to 50 in OD Monopoles, 10 ft face, includes (12) 2-3/8" x 96" pipes

Product Classification

Product Type Monopole T-frame kit

General Specifications

Mounting Monopole, 381–1270 mm (15–50 in) OD

Pipe, quantity 12

Sectors, quantity 3

Dimensions

Height 2,438.4 mm | 96 in

Face Width 3,048 mm | 10 ft

Width 3,048 mm | 120 in

Pipe Length 2,438.4 mm | 96 in

Mounting Diameter, maximum 1270 mm | 50 in

Mounting Diameter, minimum 381 mm | 15 in

Pipe Outer Diameter 60.96 mm | 2.4 in

Stand-off Distance 914.4 mm | 36 in

Material Specifications

Material Type Hot dip galvanized steel

Mechanical Specifications

Wind Rating Test Method TIA/EIA-222-G

Packaging and Weights

MC-S10M-12-96

Included	Pipe mounts Plain end pipes (12) Ring mount Square support rail Stand-off arms
Packaging quantity	1
Weight, net	582.685 kg 1,284.6 lb