


1-2105028-6

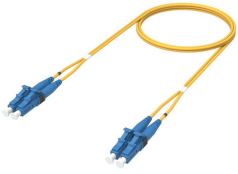

Fiber Optic Patch Cord, OS2, LC/LC duplex, 1.8 mm LSZH & OFNR, 16 m, yellow

Product Classification

| | |
|------------------------------|--|
| Regional Availability | Asia Australia/New Zealand China India |
| Portfolio | CommScope® |
| Product Type | Fiber patch cord, duplex |
| Product Series | 210 |

General Specifications


| | |
|-------------------------------|----------------|
| Connector A, quantity | 2 |
| Color, boot A | Blue |
| Color, connector A | Blue |
| Connector B, quantity | 2 |
| Color, boot B | Blue |
| Color, connector B | Blue |
| Interface, Connector A | LC/UPC |
| Interface, Connector B | LC/UPC |
| Jacket Color | Yellow |
| Polarity | Pairs, flipped |
| Total Fibers, quantity | 2 |

Dimensions

| | |
|-----------------------------|-------------------|
| Cord Length | 16 m 52.493 ft |
| Diameter Over Jacket | 1.8 mm 0.071 in |

Ordering Tree

1-2105028-6

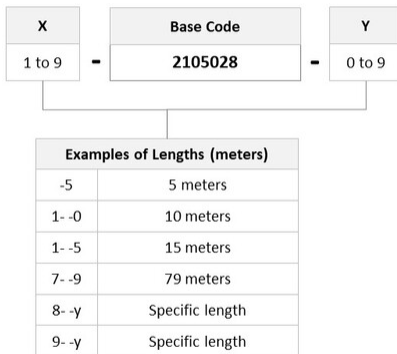

Optical Specifications

| | |
|---|------------|
| Fiber Mode | Singlemode |
| Fiber Type | OS2 |
| Insertion Loss, maximum, connector A | 0.3 dB |
| Insertion Loss, maximum, connector B | 0.3 dB |
| Return Loss, minimum, connector A | 50 dB |
| Return Loss, minimum, connector B | 50 dB |

Environmental Specifications

| | |
|--------------------------------|---|
| Environmental Space | Dual Rated LSZH/Riser |
| Qualification Standards | IEC 60332-1 IEC 60332-3 IEC 60754 IEC 61034 |

Packaging and Weights

| | |
|---------------------------|---|
| Packaging quantity | 1 |
|---------------------------|---|

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|---|
| CHINA-ROHS | Above maximum concentration value |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant/Exempted |
| UK-ROHS | Compliant/Exempted |

1-2105028-6

