


2105084-3

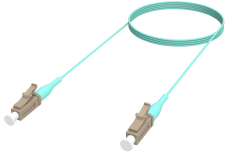

Fiber Optic Patch Cord, Simplex, 0.9mm, LSZH, Multimode OM4, LC/UPC to LC/UPC, Aqua, 3 m

Product Classification

Regional Availability	Asia Australia/New Zealand China India
Portfolio	CommScope®
Product Type	Fiber patch cord, simplex
Product Series	210

General Specifications


Connector A, quantity	1
Color, boot A	Aqua
Color, connector A	Beige
Connector B, quantity	1
Color, boot B	Aqua
Color, connector B	Beige
Interface, Connector A	LC/UPC
Interface, Connector B	LC/UPC
Jacket Color	Aqua
Total Fibers, quantity	1

Dimensions

Cord Length	3 m 9.843 ft
Diameter Over Jacket	0.9 mm 0.035 in

Ordering Tree

2105084-3

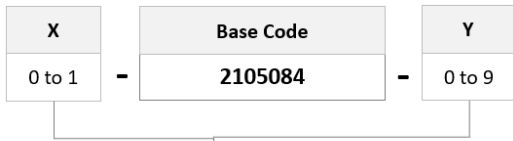

Examples of Lengths (meters)	
-1	1 meters
-2	2 meters
-3	3 meters
1--0	10 meters

Mechanical Specifications

Cable Retention Strength, maximum 1.00 lb @ 0° | 1.00 lb @ 90°

Optical Specifications

Fiber Mode Multimode
Fiber Type OM4, LazrSPEED®
Insertion Loss, maximum 0.3 dB
Return Loss, minimum 27 dB

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space Low Smoke Zero Halogen (LSZH)

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted

