


URXRVQX7R

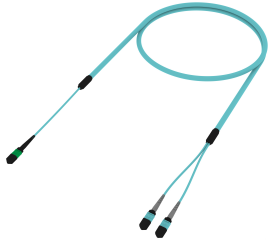

Ultra Low Loss OM4, 16F MM APC MPO (Unpinned) to 8F MPO (pinned), Fiber Extension Cable Assembly, 16-Fiber, Dual rate (LSZH/RISER)

Product Classification

Regional Availability	Australia/New Zealand Europe Latin America Middle East/Africa
Portfolio	CommScope®
Product Type	Fiber array cable assembly
Product Brand	Propel
Ordering Note	Can only be used with CXP transceivers For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Color, boot A	Red
Color, connector A	Aqua
Color, boot B	Black
Color, connector B	Aqua
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-16/APC Female
Interface Feature, connector A	QSFP configuration
Interface, Connector B	MPO-08/UPC Male
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Total Fibers, quantity	16

Dimensions

Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

URXRVQX7R

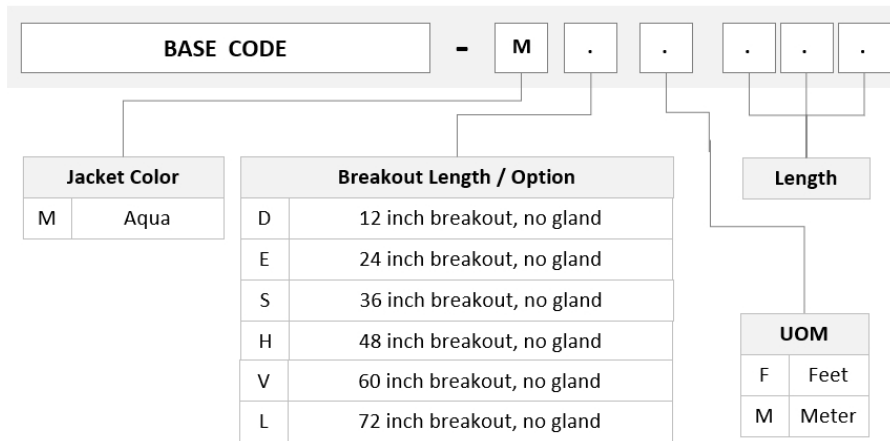

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0° | 4.40 lb @ 90°

Optical Specifications

Fiber Mode Multimode | Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Dual Rated LSZH/Riser | Indoor

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



Included Products

- 860633308 – MPO8, ULTRA LOW LOSS, MALE, OM3/4, AQUA, 3m
- 860659159 – Fiber Optic Connector Kit, multimode, OM3/OM4, MPO-16/APC, ULL, non-pinned, green, for 3

URXRVQX7R

mm cable