


TES-SS-MSK6 | BACK TO BACK CROSSOVER

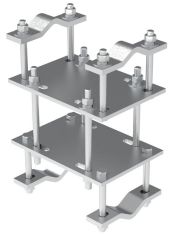

Dual Cross Over Plate, Mounts (2) 3-1/2" to 4-1/2" Pipes to 4" or 6" Square Tube

Product Classification

Product Type Clamp plate

General Specifications

Mounting Crossover plate

Dimensions

Mounting Diameter 2, maximum 152.4 mm | 6 in

Mounting Diameter 2, minimum 101.6 mm | 4 in

Mounting Diameter, maximum 114.3 mm | 4.5 in

Mounting Diameter, minimum 88.9 mm | 3.5 in

Material Specifications

Material Type Hot dip galvanized steel

Environmental Specifications

EPA with 1/2 in (12 mm) radial ice ft²

Packaging and Weights

Included Plates | U-bolts

Packaging quantity 1

* Footnotes

EPA with 1/2 in (12 mm) radial ice EPA—Effective Projected Area