


VisiPORT™ Controller

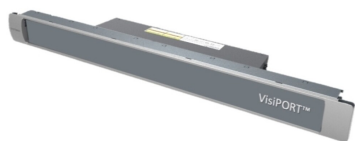

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	SYSTIMAX®
Product Type	Controller unit
Product Brand	VisiPORT™
Product Series	VisiPORT

General Specifications

Color	Cool gray
--------------	-----------

Dimensions

Height	44.45 mm 1.75 in
Width	19 mm 0.748 in

Electrical Specifications

Input Voltage	100–240 Vac
Output Current at Voltage, continuous	2.08 A @ 12 Vdc
Power Frequency	50–60 Hz

Material Specifications

Material Type	Acrylonitrile butadiene styrene (ABS) Polycarbonate Steel
----------------------	---

Environmental Specifications

Operating Temperature	0 °C to +50 °C (+32 °F to +122 °F)
Storage Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Relative Humidity	Up to 95%, non-condensing
Flammability Rating	UL 94 V-0

760258085 | VisiP-CNTRL

Safety Standard CE | RCM | UL

Packaging and Weights

Included 16 in panel bus jumper | 7 ft patch cord | Forty-four position bus panel
Packaging quantity 1
Weight, net 1.288 kg | 2.84 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

