


MP-PP13M4-16C-120

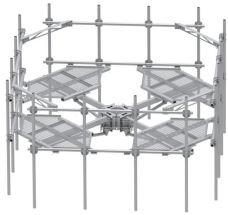

PIM Optimized Adjustable 4-Sector Monopole Platform with 13ft Face - 2-7/8in OD Face Pipes & Top Rail - Includes (16) 2-7/8in OD x 120in Antenna Pipes

Product Classification

Product Type	Co-location platform
Product Brand	PIM-guard

General Specifications

Mounting	Monopole, 381–1143 mm (15–45 in) OD
Pipe, quantity	16
Sectors, quantity	4

Dimensions

Face Width	3,962 mm 13 ft
Platform Width	3,962.4 mm 156 in
Width	3,962.4 mm 156 in
Pipe Length	3,048 mm 120 in
Face Support Pipe Diameter	73.152 mm 2.88 in
Mounting Diameter, maximum	1,143 mm 45 in
Mounting Diameter, minimum	381 mm 15 in
Pipe Outer Diameter	73.152 mm 2.88 in

Material Specifications

Material Type	Hot dip galvanized steel
----------------------	--------------------------

Mechanical Specifications

Wind Rating Test Method	TIA/EIA-222
--------------------------------	-------------

MP-PP13M4-16C-120

Packaging and Weights

Included	Plain end pipes Platform Rail Ring mount
Packaging quantity	1
Weight, net	2,303.886 kg 5,079.2 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

