


# UGBKIT-0412-G

---

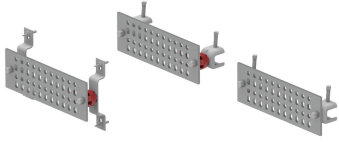

Galvanized Ground Buss Bar Kit, 1/4 in x 4 in x 12 in

## Product Classification

<b>Product Type</b>	Grounding bar
<b>Product Brand</b>	HELIAX®
<b>Ordering Note</b>	ANDREW® non-standard product

## Dimensions

<b>Height</b>	101.6 mm   4 in
<b>Length</b>	304.8 mm   12 in
<b>Material Thickness</b>	6.35 mm   0.25 in
<b>Hole Size</b>	7/16 in   7/16 in x 5/8 in
<b>Hole Distance, center to center</b>	19.05 mm   0.75 in

## Material Specifications

<b>Material Type</b>	Galvanized steel
----------------------	------------------

## Packaging and Weights

<b>Included</b>	Galvanized angle adapter   Grounding bar   Insulators   Mounting brackets   Universal hardware
<b>Packaging quantity</b>	1

## Included Products

GB-HK-DPU	– Universal Buss Bar Installation Hardware Kit, UL467 Compliant
-----------	---

# GB-HK-DPU



## Universal Buss Bar Installation Hardware Kit, UL467 Compliant

### Product Classification

<b>Product Type</b>	Attachment kit
<b>Product Brand</b>	HELIAX®
<b>Ordering Note</b>	ANDREW® standard product in the United States and Canada

### General Specifications

<b>Accessories</b>	Grounding Bars
--------------------	----------------

### Packaging and Weights

<b>Height, packed</b>	170.18 mm   6.7 in
<b>Width, packed</b>	129.54 mm   5.1 in
<b>Length, packed</b>	99.06 mm   3.9 in
<b>Included</b>	Angle adapters   Drive pin anchor   Insulators, Mounting brackets   Universal hardware
<b>Packaging quantity</b>	1
<b>Weight, gross</b>	2.6 kg   5.732 lb

### Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.andrew.com/ProductCompliance">www.andrew.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

